

# Hexagonal nut **DIN 934**



## SHNA SHN

### Steel Class 6181 or stainless steel Class A2


- Conforms to DIN 934
- Bore chamfered at  $120^\circ \pm 10^\circ$
- Exterior chamfered at  $30^\circ$
- Standard pitch
- Materials:
  - Chromed steel Class 6181
  - Stainless steel 303/304 Class A2
  - Max working temperature  $430^\circ\text{C}$
- Sold by the pack



Steel or  
stainless steel

### Options

- Also available in A4/316 stainless steel
- Fine threaded (SHN-F or N-F)

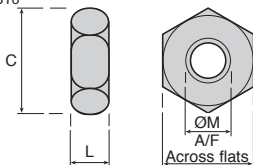

### DISCOUNTS

N° packs	1+	6+	11+
Discounts	List -10%	On request	

Part number	Thread	ØM	Pitch	A/F	C	L	Qty per pack	Stock*	Price each 1 to 5
<b>Steel class 6181</b>									
SHNA-3/B	M3	0,50	5,5	6,01	2,4	500	-		5,27 €
SHNA-4/B	M4	0,70	7,0	7,66	3,2	500	-		2,92 €
SHNA-5/B	M5	0,80	8,0	8,79	4,0	500	-		2,99 €
SHNA-6/B	M6	1,00	10,0	11,05	5,0	500	-		6,45 €
SHNA-8/B	M8	1,25	13,0	14,38	6,5	200	-		5,51 €
SHNA-10/B	M10	1,50	17,0	18,90	8,0	100	-		6,10 €
SHNA-12/B	M12	1,75	19,0	21,10	10,0	50	-		4,48 €
SHNA-16/B	M16	2,00	24,0	26,75	13,0	25	-		4,48 €
SHNA-20/B	M20	2,50	30,0	32,95	16,0	25	-		8,52 €
<b>Stainless steel (class A2)</b>									
SHN-1.6/B	M1,6	0,35	3,2	3,48	1,0	500	-		87,20 €
SHN-2/B	M2	0,40	4,0	4,32	1,6	2000	✓		32,96 €
SHN-2.5/B	M2,5	0,45	5,0	5,45	2,0	500	✓		11,59 €
SHN-3/B	M3	0,50	5,5	6,01	2,4	1000	✓		13,36 €
SHN-4/B	M4	0,70	7,0	7,66	3,2	500	✓		10,79 €
SHN-5/B	M5	0,80	8,0	8,79	4,0	500	✓		14,73 €
SHN-6/B	M6	1,00	10,0	11,05	5,0	200	✓		9,14 €
SHN-8/B	M8	1,25	13,0	14,38	6,5	100	✓		10,34 €
SHN-10/B	M10	1,50	17,0	18,90	8,0	100	✓		15,71 €
SHN-12/B	M12	1,75	19,0	21,10	10,0	100	✓		25,57 €
SHN-14/B	M14	2,00	22,0	24,49	11,0	50	✓		15,44 €
SHN-16/B	M16	2,00	24,0	26,75	13,0	50	✓		37,65 €
SHN-20/B	M20	2,50	30,0	32,95	16,0	50	✓		46,55 €
SHN-24/B	M24	3,00	36,0	39,55	19,0	25	-		55,28 €

\*Depending to availability - Dimensions in mm

## Our other products



CLR

Gas spring, Straight clevis for use with a male clevis



CHA35

Hinges and joints, Hinge



PXHG25

Crossed helical gear - precision range, 35NCD6 Pre-hardened steel



 
UC

Universal joint - steel, Double



BAN

Angular clamp, Universal



T2

Synchronous pulley, T2.5 aluminium



LFM2

Trapezoidal rolled leadscrew, Medium carbon steel - 2 threads



SLB

Indexing plunger, stainless steel



SCA

Cable clamp, Steel



BOXsap

Spring pin, Boxed set - Split ISO 8752



R203

Extra-thick die spring, Light



AT10\_32

Synchronous pulley, AT10 steel

## Complementary products



SHW

Washer - DIN 125, A2 Stainless steel



VCMB

Dual-thread screw wood/metal, Stainless steel



NIN

Self locking nut - DIN 985, A2 Stainless steel



WING

Manually tightened wing nut, Stainless steel DIN 314/315