

# Hexagonal nut **DIN 934**



## SHNA SHN

### Steel Class 6181 or stainless steel Class A2


- Conforms to DIN 934
- Bore chamfered at  $120^\circ \pm 10^\circ$
- Exterior chamfered at  $30^\circ$
- Standard pitch
- Materials:
  - Chromed steel Class 6181
  - Stainless steel 303/304 Class A2
  - Max working temperature  $430^\circ\text{C}$
- Sold by the pack



Steel or  
stainless steel

### Options

- Also available in A4/316 stainless steel
- Fine threaded (SHN-F or N-F)

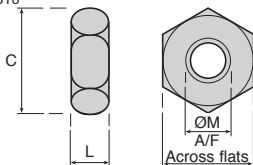


### DISCOUNTS

N° packs	1+	6+	11+
Discounts	List -10%	On request	

Part number	Thread	ØM	Pitch	A/F	C	L	Qty per pack	Stock*	Price each 1 to 5
<b>Steel class 6181</b>									
SHNA-3/B	M3	0,50	5,5	6,01	2,4	500	-		5,27 €
SHNA-4/B	M4	0,70	7,0	7,66	3,2	500	-		2,92 €
SHNA-5/B	M5	0,80	8,0	8,79	4,0	500	-		2,99 €
SHNA-6/B	M6	1,00	10,0	11,05	5,0	500	-		6,45 €
SHNA-8/B	M8	1,25	13,0	14,38	6,5	200	-		5,51 €
SHNA-10/B	M10	1,50	17,0	18,90	8,0	100	-		6,10 €
SHNA-12/B	M12	1,75	19,0	21,10	10,0	50	-		4,48 €
SHNA-16/B	M16	2,00	24,0	26,75	13,0	25	-		4,48 €
SHNA-20/B	M20	2,50	30,0	32,95	16,0	25	-		8,52 €
<b>Stainless steel (class A2)</b>									
SHN-1.6/B	M1,6	0,35	3,2	3,48	1,0	500	-		87,20 €
SHN-2/B	M2	0,40	4,0	4,32	1,6	2000	✓		32,96 €
SHN-2.5/B	M2,5	0,45	5,0	5,45	2,0	500	✓		11,59 €
SHN-3/B	M3	0,50	5,5	6,01	2,4	1000	✓		13,36 €
SHN-4/B	M4	0,70	7,0	7,66	3,2	500	✓		10,79 €
SHN-5/B	M5	0,80	8,0	8,79	4,0	500	✓		14,73 €
SHN-6/B	M6	1,00	10,0	11,05	5,0	200	✓		9,14 €
SHN-8/B	M8	1,25	13,0	14,38	6,5	100	✓		10,34 €
SHN-10/B	M10	1,50	17,0	18,90	8,0	100	✓		15,71 €
SHN-12/B	M12	1,75	19,0	21,10	10,0	100	✓		25,57 €
SHN-14/B	M14	2,00	22,0	24,49	11,0	50	✓		15,44 €
SHN-16/B	M16	2,00	24,0	26,75	13,0	50	✓		37,65 €
SHN-20/B	M20	2,50	30,0	32,95	16,0	50	✓		46,55 €
SHN-24/B	M24	3,00	36,0	39,55	19,0	25	-		55,28 €

\*Depending to availability - Dimensions in mm
 
## Our other products




PF30  
Worm and wheel gear reducer, up to 8.80 Nm



UGH25  
H Type Guide units, For Ø25 actuators



 
VBFP  
Small 6 lobe threaded handle - female, Duroplast - Stainless steel



H0  
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



 DHX  
Dowel pin internal thread, Extractable DIN 7979D



M0  
Worm and wheel set, Machined plastic (delrin)



ACL-PR  
Joining plate for aluminium profile, Right angled connection



RDE-B  
Sealing washer Hygienic Usit®, Stainless steel - Blue EPDM



BOX-TOR-MAX  
Box set of Nitrile O-rings in nitrile, 2.90 x



AT10-50ECO  
AT type timing pulley, Economy range -



SDG  
Adjustable guide support bracket,



UGPC  
Actuator guide kit, Short bearing

## Complementary products



SHW  
Plain washer, A2 Stainless steel



NIN  
Self-locking nut, A2 Stainless steel



VCMB  
Dual-thread screw wood/metal, Stainless steel



WING  
Manually tightened wing nut, Stainless steel DIN 314/315