


# Hexagonal nut **DIN934**

Brass

SHNBR

- Nut conforming to DIN934
- Material:  
Brass

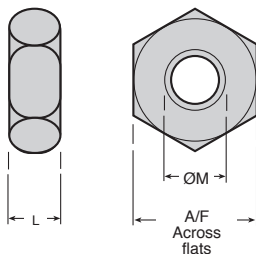

## DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØM	Pitch	L	A/F		Price each
				Across flats	Qty/pack	1 to 5
SHN-4/BR/B	M4	0,70	3,2	7	100	4,54 €
SHN-5/BR/B	M5	0,80	4	8	100	5,74 €
SHN-6/BR/B	M6	1,00	5	10	100	10,81 €
SHN-8/BR/B	M8	1,25	6,5	13	100	22,48 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel


cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

193
 
## Our other products



Drawn ground round bar, 100C6 steel bar



Moulded plastic bevel gear (nylon), 2:1



Latch with locking system, Aluminium



 
Eco. range steel bevel gear, 2:1



Crossed helical gear crossed axis at 90°, Steel 20NCD2



Wheel pivoting with plate, Polyurethane - Aluminium rim (Free running)



RPP type belt per metre, RPP14 Steel cored polyurethane



Spur gear - precision range, Case hardened steel 20NCD2



Roller for aluminium profile, Hollow roller ø12



Castor for aluminium profile, With brake



Bearing block for leadscrew, Floating Drylin® bearing block



Mounting sleeve for lock pin, Nickel-plated steel or Stainless steel

## Complementary products



 
Hexagonal headed screw VTH - DIN933, Brass



Wing screw, hand tightened DIN316, Brass DIN 316



Manually tightened wing nut DIN315, Brass DIN 315



Washer - DIN125, Brass