

Steel Class 6181  
or stainless steel Class A2

**SHNA**  
**SHN**

- **Conforms to DIN 934**
- Bore chamfered at  $120^\circ \pm 10^\circ$
- Exterior chamfered at  $30^\circ$
- Standard pitch
- Materials:
  - Chromed steel Class 6181
  - Stainless steel 303/304 Class A2
  - Max working temperature  $430^\circ\text{C}$
- Sold by the pack




Steel or  
stainless steel

## Options

- Also available in A4/316 stainless steel
- Fine threaded (SHN-F or N-F)

## Accessories

- Box set of hexagonal nuts DIN934
- BOX-SHNA**
- (tome 1 p.654)

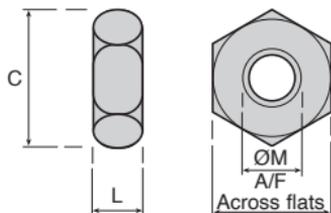

## DISCOUNTS

N° packets	1+	6+	11+
Discounts	List -10%	On request	

Part number	Thread	ØM	Pitch	A/F	C	L	Qty per packet	Stock*	Price per packet
<b>Steel class 6181</b>									
SHNA-3/B	M3		0,50	5,5	6,01	2,4	500	✓	8,71 €
SHNA-4/B	M4		0,70	7,0	7,66	3,2	500	✓	6,59 €
SHNA-5/B	M5		0,80	8,0	8,79	4,0	500	✓	5,98 €
SHNA-6/B	M6		1,00	10,0	11,05	5,0	500	✓	11,45 €
SHNA-8/B	M8		1,25	13,0	14,38	6,5	200	✓	9,16 €
SHNA-10/B	M10		1,50	17,0	18,90	8,0	100	✓	7,64 €
SHNA-12/B	M12		1,75	19,0	21,10	10,0	50	✓	5,60 €
SHNA-16/B	M16		2,00	24,0	26,75	13,0	25	✓	4,97 €
SHNA-20/B	M20		2,50	30,0	32,95	16,0	25	✓	9,48 €
<b>Stainless steel (class A2)</b>									
SHN-1.6/B	M1,6		0,35	3,2	3,48	1,0	1000	-	117,73 €
SHN-2/B	M2		0,40	4,0	4,32	1,6	1000	✓	18,37 €
SHN-2.5/B	M2,5		0,45	5,0	5,45	2,0	1000	✓	20,40 €
SHN-3/B	M3		0,50	5,5	6,01	2,4	1000	✓	14,88 €
SHN-4/B	M4		0,70	7,0	7,66	3,2	1000	✓	18,77 €
SHN-5/B	M5		0,80	8,0	8,79	4,0	1000	✓	26,88 €
SHN-6/B	M6		1,00	10,0	11,05	5,0	100	✓	5,98 €
SHN-8/B	M8		1,25	13,0	14,38	6,5	100	✓	11,52 €
SHN-10/B	M10		1,50	17,0	18,90	8,0	100	✓	17,50 €
SHN-12/B	M12		1,75	19,0	21,10	10,0	100	✓	28,51 €
SHN-14/B	M14		2,00	22,0	24,49	11,0	100	✓	34,42 €
SHN-16/B	M16		2,00	24,0	26,75	13,0	50	✓	42,01 €
SHN-20/B	M20		2,50	30,0	32,95	16,0	50	-	51,92 €
SHN-24/B	M24		3,00	36,0	39,55	19,0	25	-	61,68 €

\* Depending to availability - Dimensions in mm

# Hexagonal nut **DIN934**

## SHNBR

## Brass


- Nut conforming to DIN934

- Material:

Brass

### Info.

- Supplied by pack

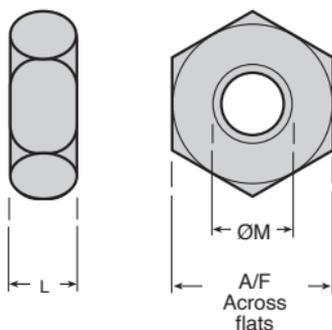

### DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part number	ØM	Pitch	L	A/F Across flats	Qty. per packet	Price per packet
SHN-4/BR/B	M4	0,70	3,2	7	100	6,55 €
SHN-5/BR/B	M5	0,80	4	8	100	6,02 €
SHN-6/BR/B	M6	1,00	5	10	100	12,12 €
SHN-8/BR/B	M8	1,25	6,5	13	100	24,89 €

All dimensions in mm