


# Hexagonal nut **DIN934**

Brass

SHNBR

- Nut conforming to DIN934
- Material:  
Brass

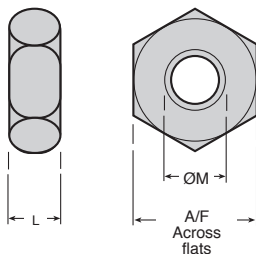

## DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØM	Pitch	L	A/F		Price each
				Across flats	Qty/pack	1 to 5
SHN-4/BR/B	M4	0,70	3,2	7	100	4,54 €
SHN-5/BR/B	M5	0,80	4	8	100	5,74 €
SHN-6/BR/B	M6	1,00	5	10	100	10,81 €
SHN-8/BR/B	M8	1,25	6,5	13	100	22,48 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel


cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

193
 
## Our other products




IN2

Internal gear,  
Machined plastic  
(delrin)



CQA30

Accessory for  
adjustment slide-  
system, 30

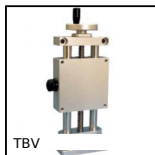

TBV

Manual lifting tables,  
20kg



DOMI30

Domino 30 adjustable  
slide, Slide DOMILINE  
30



MSP23

Masterplate®  
glueable insert Ø23,  
Cylindrical Ø23 with  
threaded s...



T5-10ECO

T type timing pulley,  
Economy range - T5  
aluminium



ALIDR30

12 and 24V DC power  
supplies, 1,5 A and 2  
A



DFG

Flat suction cup,  
silicon



APB\_T

Adjusting rod for  
clamp - Female, Bored



BCM\_CC

Modular cylindrical  
brush, Horsehair  
bristles



KB\_OP

Open precision linear  
bearing, Precision -  
steel



CHMR110

Worm and wheel gear  
reducer, up to 980  
Nm

## Complementary products



VTHbr

Hexagonal headed  
screw VTH - DIN933,  
Brass



WINGbr

Wing screw, hand  
tightened DIN316,  
Brass DIN 316



WINGbrEcrou

Manually tightened  
wing nut DIN315,  
Brass DIN 315



SHWbr

Washer - DIN125,  
Brass