


# Hexagonal nut **DIN934**

Brass

SHNBR

- Nut conforming to DIN934
- Material:  
Brass

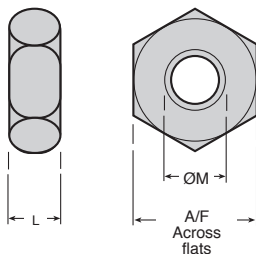

## DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØM	Pitch	L	A/F		Price each
				Across flats	Qty/pack	
SHN-4/BR/B	M4	0,70	3,2	7	100	4,54 €
SHN-5/BR/B	M5	0,80	4	8	100	5,74 €
SHN-6/BR/B	M6	1,00	5	10	100	10,81 €
SHN-8/BR/B	M8	1,25	6,5	13	100	22,48 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

193

## Our other products



RAM30  
Manual bevel  
gearbox, Bevel



BPL  
Ball transfer unit light  
duty, Light



LSAG  
Precision linear rotary  
ball spline, Rail - from  
514 N to 15386 N



UTKswrr  
V shaped channel  
UtilTrak®, V rail



 
BOXKU  
Boxed set of half  
round (Woodruff) keys  
NFE22179, Boxed set  
of half ...



DB  
Steel bevel gear, 2:1



ACAss  
Stainless steel splined  
shaft, Stainless steel



H1  
Crossed helical gear  
crossed axis at 90°,  
Machined plastic  
(delrin)



PML  
Solid foot mount for  
heavy loads, Ø 100,  
...



HG8-ECO  
Eco range Spur gear,  
Steel C45



HLC19  
Right angle spiro  
bevel gearbox, Up to  
...



GBS  
Nut for ballscrew,  
Flanged ballscrew nut

## Complementary products



 
VTHbr  
Hexagonal headed  
screw VTH - DIN933,  
Brass



WINGbr  
Wing screw, hand  
tightened DIN316,  
Brass DIN 316



WINGbrEcrou  
Manually tightened  
wing nut DIN315,  
Brass DIN 315



SHWbr  
Washer - DIN125,  
Brass