


# Hexagonal nut **DIN934**

Brass

**SHNBR**

- Nut conforming to DIN934
- Material:  
Brass

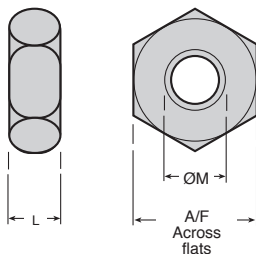

## DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØM	Pitch	L	A/F		Price each
				Across flats	Qty/pack	
SHN-4/BR/B	M4	0,70	3,2	7	100	4,54 €
SHN-5/BR/B	M5	0,80	4	8	100	5,74 €
SHN-6/BR/B	M6	1,00	5	10	100	10,81 €
SHN-8/BR/B	M8	1,25	6,5	13	100	22,48 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

193

## Our other products



BDP1R  
Adjustable support  
arm, Single clamp



PRF-SMA  
Closing system for  
aluminium profile,  
Easily adjustable lock



RHTTcss  
High Temperature  
Castor, up to 200kg



HTD14M\_85  
HTD Heavy duty  
timing pulley, HTD14  
Steel



LWL  
Linear ball slide -  
Stainless steel balls,  
Rail - from 514 N to  
1670...



TSM T10M  
T type timing belt per  
metre, T5 Steel cored  
polyurethane



M0  
Worm and wheel set,  
Machined plastic  
(delrin)



HG6-ECO  
Eco range Spur gear,  
Steel C45



GG2  
Ground spur gear,  
Heat treated steel



VTSM  
Ball head screws  
Hygienic Design®,



BLHT70  
Right angled gearbox,  
from 26 to 128 Nm



DP  
Dowel pin, Solid ISO  
2338

## Complementary products



 
VTHbr  
Hexagonal headed  
screw VTH - DIN933,  
Brass



WINGbr  
Wing screw, hand  
tightened DIN316,  
Brass DIN 316



WINGbrEcrou  
Manually tightened  
wing nut DIN315,  
Brass DIN 315



SHWbr  
Washer - DIN125,  
Brass