


Hexagonal nut **DIN934**

Brass

SHNBR

- Nut conforming to DIN934
- Material:
Brass

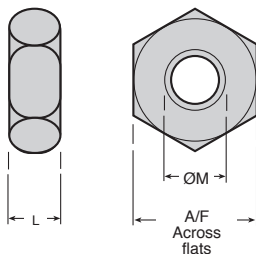

DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØM	Pitch	L	A/F		Price each
				Across flats	Qty/pack	
SHN-4/BR/B	M4	0,70	3,2	7	100	4,54 €
SHN-5/BR/B	M5	0,80	4	8	100	5,74 €
SHN-6/BR/B	M6	1,00	5	10	100	10,81 €
SHN-8/BR/B	M8	1,25	6,5	13	100	22,48 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



HTD8M_20

HTD Heavy duty timing pulley, HTD8 Cast



VELprf

Clip-on base for hook-and-loop strip, Polyamide



PRF_ART

Articulated bracket for use with aluminium profile, With clamping ha...



PSG25S

Spur gear - precision range, Stainless steel 316



 
ETGamme

Extension springs DIN2097, DIN 2097



STC

Shock Absorber - stop collar, Universal flange



TBV

Manual lifting tables, For vertical strokes - Ø 25 mm column



TCSH

Automatic chain tensioner, With support



TPEf

Castor for aluminium profile, Fixed



UGH40

H Type Guide units, For Ø40 actuators



HS

Hexagonal spacer, Stainless steel 303



ATZY

Diabolo shaped elasto mount, Steel

Complementary products



VTHbr

Hexagonal headed screw VTH - DIN933, Brass




WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315

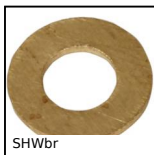

SHWbr

Washer - DIN125, Brass