

Shoulder screw **stainless steel 303**

SHS


Stainless steel 550 N/mm²

- **Material: Stainless steel 303**
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance: 550N/mm²
- **Not sold individually, please contact us for details**



Uses

- For use in harsh environments

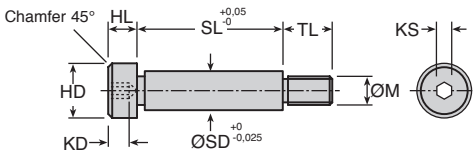

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD								
SHS3-4	M3	3,987	4,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-5	M3	3,987	5,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-6	M3	3,987	6,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-8	M3	3,987	8,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-10	M3	3,987	10,013	6	3	4	2,0	1,6	✓	6,39 €

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread									Stock*	Price each 1 to 5
	ØM	SD	SL	HD	HL	TL	KS	KD			
SHS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	9,08 €	
SHS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	9,08 €	
SHS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	7,27 €	
SHS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	7,27 €	
SHS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	9,72 €	
SHS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	10,51 €	
SHS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	10,51 €	
SHS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	10,51 €	
SHS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	✓	13,32 €	
SHS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	✓	13,32 €	
SHS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	16,28 €	
SHS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	✓	16,28 €	
SHS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	16,28 €	
SHS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	16,28 €	
SHS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	✓	18,73 €	
SHS8-30	M8	9,987	30,013	14	7	12	5,0	4,0	✓	18,73 €	
SHS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	✓	36,91 €	

*Depending on availability - Dimensions in mm

Our other products



PSG05HC
Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



SLB
Indexing plunger, stainless steel



PRF_PA
Angle plate for aluminium profile, Adjustable plate



LVT
Miniature motorised actuator 2A, 2 ampers




FF40
Offset spur gear reducer, from 59 to 210 Nm



BPFLss
Pressed stainless steel flange bearing, Stainless steel



METC
Flanged sintered bronze bush, Self-lubricating sintered bronze

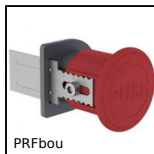

PRFbou
Emergency release button for aluminium profile, Emergency release bu...



RPCplss
Swivel castor with plate, Stainless steel - Polyamide



BAGtr
Lead screw clamping collar, Aluminium



RFK28B
Hypoid gearbox - Stainless steel, up to 130 Nm



CLG2
Moulded plastic spur gear, Moulded plastic (nylon)

Complementary products



HSS
Shoulder screw ISO7379, Hardened Steel class 12.9



SHSS
Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



SHW
Plain washer, A2 Stainless steel



SHN
Hexagonal nut DIN934, A2 Stainless steel