


# Shoulder screw **ISO 7379**



## HSS

## Hardened steel Class 12.9

- **Shoulder screws, quality class 12.9**
- For centering as well as holding
- Material: Hardened steel 33-38 HRC (oil-hardened)
- Traction resistance 1220N/mm<sup>2</sup>
- Shear strength 624N/mm<sup>2</sup>
- Minimum elongation: 8%
- Working temperature: -50°C to +300°C
- **Not sold individually, please contact us for details**

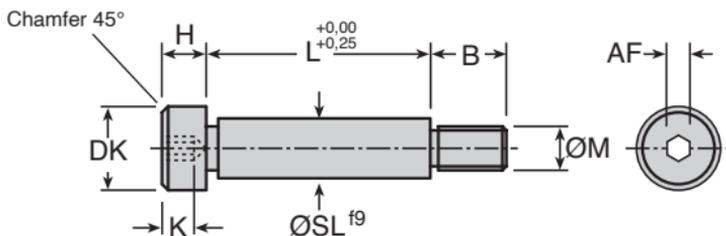

ØSL	ØM	Traction Force (kN)			Tightening torque (Nm)
		Thread	Shoulder	Groove	
6	M5	16,99	20,47	7,62	7,61
8	M6	24,03	36,38	10,90	13,14
10	M8	43,77	56,86	20,81	33,63
12	M10	69,38	81,88	33,79	60,56
16	M12	100,52	145,55	49,80	120,62

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread ØM	L	Pitch	b	dk	k	ØsL	H	AF	Stock*	Price each
											1 to 5
HSS5-10	M5	10	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,56 €
HSS5-12	M5	12	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,56 €
HSS5-16	M5	16	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,72 €
HSS5-20	M5	20	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,72 €
HSS5-25	M5	25	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,79 €
HSS5-30	M5	30	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,79 €
HSS5-40	M5	40	0,80	9,75	10,22	2,4	Ø6 <sup>-0.010 / -0.040</sup>	4,5	3	✓	3,84 €

\*Depending on availability - Dimensions in mm

## DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	IIST	-10%	-15%	-20%	-30%	-55%	On request





Part number	Thread ØM	L	Pitch	b	dk	k	ØsL	H	AF	Stock*	Price each 1 to 5
HSS6-12	M6	12	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	3,89 €
HSS6-16	M6	16	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	4,00 €
HSS6-20	M6	20	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	4,16 €
HSS6-25	M6	25	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	4,16 €
HSS6-30	M6	30	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	4,35 €
HSS6-40	M6	40	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	4,50 €
HSS6-50	M6	50	1,00	11,25	13,27	3,3	Ø8 <sup>-0,013</sup> <sub>-0,049</sub>	5,5	4	✓	4,62 €
HSS8-16	M8	16	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	4,74 €
HSS8-20	M8	20	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	4,74 €
HSS8-25	M8	25	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	4,90 €
HSS8-30	M8	30	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	5,99 €
HSS8-40	M8	40	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	6,35 €
HSS8-50	M8	50	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	6,42 €
HSS8-60	M8	60	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	6,42 €
HSS8-70	M8	70	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	7,05 €
HSS8-80	M8	80	1,25	13,25	16,27	4,2	Ø10 <sup>-0,013</sup> <sub>-0,049</sub>	7,0	5	✓	7,90 €
HSS10-16	M10	16	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	7,47 €
HSS10-20	M10	20	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	7,14 €
HSS10-25	M10	25	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	8,15 €
HSS10-30	M10	30	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	8,27 €
HSS10-40	M10	40	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	8,11 €
HSS10-50	M10	50	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	8,98 €
HSS10-60	M10	60	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	11,06 €
HSS10-70	M10	70	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	11,76 €
HSS10-80	M10	80	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	-	15,16 €
HSS10-90	M10	90	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	-	17,42 €
HSS10-100	M10	100	1,50	16,4	18,27	4,9	Ø12 <sup>-0,016</sup> <sub>-0,059</sub>	8,0	6	✓	20,68 €
HSS12-30	M12	30	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	✓	14,17 €
HSS12-40	M12	40	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	✓	15,32 €
HSS12-50	M12	50	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	-	15,95 €
HSS12-60	M12	60	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	✓	19,00 €
HSS12-70	M12	70	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	✓	19,72 €
HSS12-80	M12	80	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	✓	20,97 €
HSS12-90	M12	90	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	-	23,36 €
HSS12-120	M12	120	1,75	18,4	24,33	6,6	Ø16 <sup>-0,016</sup> <sub>-0,059</sub>	10,0	8	-	39,54 €

\* Depending on availability - Dimensions in mm

## HSSs

## Stainless steel A2

- **Centering and clamping function**
- Ground shoulder, tolerance  $f_9$
- **Material:**  
Stainless steel A2

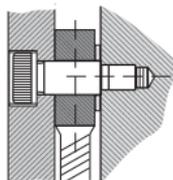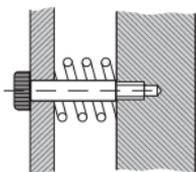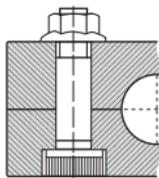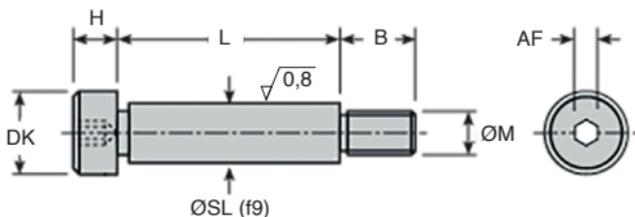

Part number	Thread		L	ØSL (f9)	B	DK	H	AF	Stock*	Price each 1 to 5
	ØM	Pas								
HSS5-10/SS/B	M5	0,80	10	6	9,50	10,22	4,5	3	✓	34,05 €
HSS5-12/SS/B	M5	0,80	12	6	9,50	10,22	4,5	3	✓	36,68 €
HSS5-16/SS/B	M5	0,80	16	6	9,50	10,22	4,5	3	-	36,56 €
HSS5-20/SS/B	M5	0,80	20	6	9,50	10,22	4,5	3	-	42,85 €
HSS5-25/SS/B	M5	0,80	25	6	9,50	10,22	4,5	3	✓	51,48 €
HSS5-30/SS/B	M5	0,80	30	6	9,50	10,22	4,5	3	✓	55,15 €
HSS5-40/SS/B	M5	0,80	40	6	9,50	10,22	4,5	3	✓	60,15 €

\*Depending on availability - Dimensions in mm

Part number	Thread		L	ØSL					Stock <sup>1</sup>	Price each 1 to 5
	ØM	Pas		(f9)	B	DK	H	AF		
HSS6-12/SS/B	M6	1,00	12	8	11,00	13,27	5,5	4	✓	39,06 €
HSS6-16/SS/B	M6	1,00	16	8	11,00	13,27	5,5	4	-	49,58 €
HSS6-20/SS/B	M6	1,00	20	8	11,00	13,27	5,5	4	✓	51,05 €
HSS6-25/SS/B	M6	1,00	25	8	11,00	13,27	5,5	4	-	52,18 €
HSS6-30/SS/B	M6	1,00	30	8	11,00	13,27	5,5	4	✓	48,03 €
HSS6-40/SS/B	M6	1,00	40	8	11,00	13,27	5,5	4	✓	59,34 €
HSS6-50/SS/B	M6	1,00	50	8	11,00	13,27	5,5	4	✓	71,92 €
HSS8-16/SS/B	M8	1,25	16	10	13,00	16,27	7	5	✓	57,39 €
HSS8-20/SS/B	M8	1,25	20	10	13,00	16,27	7	5	✓	59,26 €
HSS8-25/SS/B	M8	1,25	25	10	13,00	16,27	7	5	-	83,55 €
HSS8-30/SS/B	M8	1,25	30	10	13,00	16,27	7	5	-	54,25 €
HSS8-40/SS/B	M8	1,25	40	10	13,00	16,27	7	5	-	66,80 €
HSS8-50/SS/B	M8	1,25	50	10	13,00	16,27	7	5	-	77,92 €
HSS8-60/SS/B	M8	1,25	60	10	13,00	16,27	7	5	-	91,39 €
HSS8-70/SS/B	M8	1,25	70	10	13,00	16,27	7	5	-	102,20 €
HSS8-80/SS/B	M8	1,25	80	10	13,00	16,27	7	5	-	106,91 €
HSS10-16/SS/B	M10	1,50	16	12	16,00	18,27	9	6	✓	34,92 €
HSS10-20/SS/B	M10	1,50	20	12	16,00	18,27	9	6	✓	38,06 €
HSS10-25/SS/B	M10	1,50	25	12	16,00	18,27	9	6	-	39,80 €
HSS10-30/SS/B	M10	1,50	30	12	16,00	18,27	9	6	-	41,41 €
HSS10-40/SS/B	M10	1,50	40	12	16,00	18,27	9	6	✓	47,32 €
HSS10-50/SS/B	M10	1,50	50	12	16,00	18,27	9	6	-	47,23 €
HSS10-60/SS/B	M10	1,50	60	12	16,00	18,27	9	6	-	47,69 €
HSS10-70/SS/B	M10	1,50	70	12	16,00	18,27	9	6	-	57,62 €
HSS10-80/SS/B	M10	1,50	80	12	16,00	18,27	9	6	-	62,85 €
HSS10-100/SS/B	M10	1,50	100	12	16,00	18,27	9	6	-	67,17 €
HSS12-30/SS/B	M12	1,75	30	16	18,00	24,33	11	8	-	65,00 €
HSS12-40/SS/B	M12	1,75	40	16	18,00	24,33	11	8	✓	73,69 €
HSS12-50/SS/B	M12	1,75	50	16	18,00	24,33	11	8	-	89,74 €
HSS12-60/SS/B	M12	1,75	60	16	18,00	24,33	11	8	-	101,68 €
HSS12-70/SS/B	M12	1,75	70	16	18,00	24,33	11	8	-	111,97 €
HSS12-80/SS/B	M12	1,75	80	16	18,00	24,33	11	8	-	145,94 €
HSS12-100/SS/B	M12	1,75	100	16	18,00	24,33	11	8	-	165,24 €
HSS16-40/SS/B	M16	2,00	40	20	22,00	30,33	14	10	-	On request
HSS16-50/SS/B	M16	2,00	50	20	22,00	30,33	14	10	✓	122,00 €
HSS16-60/SS/B	M16	2,00	60	20	22,00	30,33	14	10	-	112,16 €
HSS16-70/SS/B	M16	2,00	70	20	22,00	30,33	14	10	-	142,27 €
HSS16-80/SS/B	M16	2,00	80	20	22,00	30,33	14	10	-	168,81 €

<sup>1</sup>Depending on availability - Dimensions in mm

# Shoulder screw **stainless steel 303**

## SHS

## Stainless steel 550 N/mm<sup>2</sup>


- **Material: Stainless steel 303**
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance: 550N/mm<sup>2</sup>
- **Not sold individually, please contact us for details**

### Uses

- For use in harsh environments



stainless steel

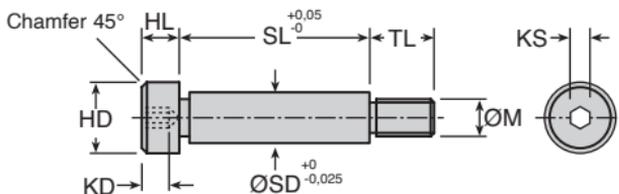

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD								
SHS3-4	M3	3,987	4,013	6	3	4	2,0	1,6	✓	8,89 €
SHS3-5	M3	3,987	5,013	6	3	4	2,0	1,6	✓	8,89 €
SHS3-6	M3	3,987	6,013	6	3	4	2,0	1,6	✓	8,89 €
SHS3-8	M3	3,987	8,013	6	3	4	2,0	1,6	✓	8,89 €
SHS3-10	M3	3,987	10,013	6	3	4	2,0	1,6	✓	8,89 €

\*Depending on availability - Dimensions in mm

## DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread									Stock*	Price each 1 to 5
	ØM	SD	SL	HD	HL	TL	KS	KD			
SHS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	8,89 €	
SHS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	8,89 €	
SHS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	✓	8,89 €	
SHS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	8,89 €	
SHS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	8,89 €	
SHS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	10,12 €	
SHS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	10,12 €	
SHS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	10,12 €	
SHS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	10,12 €	
SHS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	12,67 €	
SHS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	12,67 €	
SHS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	✓	8,89 €	
SHS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	8,89 €	
SHS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	8,89 €	
SHS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	8,89 €	
SHS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	8,89 €	
SHS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	10,12 €	
SHS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	10,12 €	
SHS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	13,57 €	
SHS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	14,65 €	
SHS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	14,65 €	
SHS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	14,65 €	
SHS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	14,65 €	
SHS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	14,65 €	
SHS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	14,65 €	
SHS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	14,65 €	
SHS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	14,65 €	
SHS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	14,65 €	
SHS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	✓	18,59 €	
SHS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	✓	18,59 €	
SHS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	25,43 €	
SHS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	✓	25,43 €	
SHS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	25,43 €	
SHS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	25,43 €	
SHS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	✓	18,37 €	
SHS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	18,37 €	
SHS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	18,37 €	
SHS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	18,37 €	
SHS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	✓	26,17 €	
SHS8-30	M8	9,987	30,013	14	7	12	5,0	4,0	✓	26,17 €	
SHS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	31,94 €	
SHS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	31,94 €	
SHS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	31,94 €	
SHS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	31,94 €	
SHS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	✓	51,58 €	

\*Depending on availability - Dimensions in mm

# Shoulder screw **stainless steel 416**


## SHSS S/steel pre-treated 850-1000N/mm<sup>2</sup>

- **Material: pre-treated stainless steel 416**  
26-32 HRC
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance 850-1000 N/mm<sup>2</sup>



### Uses

- For use in harsh environments

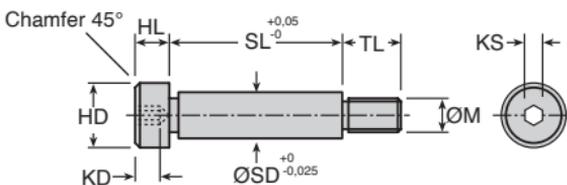

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD		Price each	
	ØM	SD								1 to 5	
SHSS3-4	M3	3,987	4,013	6	3	4	2,0	1,6		20,97	€
SHSS3-5	M3	3,987	5,013	6	3	4	2,0	1,6		20,97	€
SHSS3-6	M3	3,987	6,013	6	3	4	2,0	1,6		20,97	€
SHSS3-8	M3	3,987	8,013	6	3	4	2,0	1,6		20,97	€
SHSS3-10	M3	3,987	10,013	6	3	4	2,0	1,6		20,97	€

\*Depending on availability - Dimensions in mm

## DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD								
SHSS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	20,97 €
SHSS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	20,97 €
SHSS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	✓	20,97 €
SHSS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	20,97 €
SHSS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	20,97 €
SHSS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	23,90 €
SHSS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	23,90 €
SHSS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	23,90 €
SHSS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	23,90 €
SHSS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	29,91 €
SHSS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	29,91 €
SHSS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	-	20,97 €
SHSS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	20,97 €
SHSS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	20,97 €
SHSS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	20,97 €
SHSS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	20,97 €
SHSS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	23,90 €
SHSS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	23,90 €
SHSS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	23,90 €
SHSS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	34,37 €
SHSS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	34,37 €
SHSS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	34,37 €
SHSS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	25,59 €
SHSS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	-	25,59 €
SHSS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	25,59 €
SHSS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	25,59 €
SHSS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	25,59 €
SHSS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	25,59 €
SHSS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	-	69,08 €
SHSS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	-	69,08 €
SHSS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	-	31,97 €
SHSS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	31,97 €
SHSS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	-	52,23 €
SHSS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	39,08 €
SHSS8-20	M8	9,987	20,013	14	7	12	5,0	4,0	✓	39,08 €
SHSS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	-	45,11 €
SHSS8-30	M8	9,987	30,013	14	7	12	6,0	4,0	-	39,08 €
SHSS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	39,36 €
SHSS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	47,40 €
SHSS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	39,36 €
SHSS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	39,36 €
SHSS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	-	On request

\*Depending on availability - Dimensions in mm