

Shoulder screw **stainless steel 303**


SHS

Stainless steel 550 N/mm²

- **Material: Stainless steel 303**
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance: 550N/mm²
- **Not sold individually, please contact us for details**

Uses

- For use in harsh environments

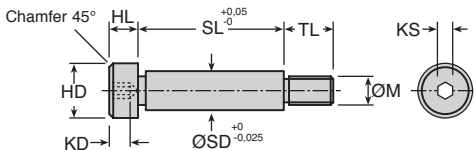

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD								
SHS3-4	M3	3,987	4,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-5	M3	3,987	5,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-6	M3	3,987	6,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-8	M3	3,987	8,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-10	M3	3,987	10,013	6	3	4	2,0	1,6	✓	6,39 €

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread								Stock*	Price each 1 to 5
	ØM	SD	SL	HD	HL	TL	KS	KD		
SHS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	6,39 €
SHS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	6,39 €
SHS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	✓	6,39 €
SHS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	6,39 €
SHS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	6,39 €
SHS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	7,27 €
SHS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	7,27 €
SHS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	7,27 €
SHS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	7,27 €
SHS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	9,08 €
SHS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	9,08 €
SHS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	✓	6,39 €
SHS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	6,39 €
SHS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	6,39 €
SHS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	6,39 €
SHS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	6,39 €
SHS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	7,27 €
SHS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	7,27 €
SHS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	9,72 €
SHS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	10,51 €
SHS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	10,51 €
SHS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	10,51 €
SHS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	10,51 €
SHS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	10,51 €
SHS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	10,51 €
SHS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	10,51 €
SHS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	10,51 €
SHS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	10,51 €
SHS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	✓	13,32 €
SHS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	✓	13,32 €
SHS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	16,28 €
SHS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	✓	16,28 €
SHS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	16,28 €
SHS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	16,28 €
SHS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	✓	13,17 €
SHS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	13,17 €
SHS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	13,17 €
SHS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	13,17 €
SHS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	✓	18,73 €
SHS8-30	M8	9,987	30,013	14	7	12	5,0	4,0	✓	18,73 €
SHS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	22,85 €
SHS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	22,85 €
SHS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	22,85 €
SHS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	22,85 €
SHS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	✓	36,91 €

 
*Depending on availability - Dimensions in mm

Our other products



CLB_M

Die cast zinc clamping lever - female, Zamak



LAT1

1A motorised linear actuator, 1 ampere



VDS

Sliding lock adjustment system, Sliding lock for oblong hole



PENV

Recessed handle, screw fixing



TM_CTM_CTF

Suction cup threaded insert, Insert for suction cup - Tread click-in



BABFCFO

Ball pin socket, Mounting collar with a oval flange



DOMI80

Connecting kits, XZ linking kit



BUH77

Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



RAGFLOW

Floway2® roller track, Roller track



GGB

Female wing knob, With blind thread



PF30NM

Worm and wheel gear reducer, up to 8.8 Nm



EPE

Wing nuts Hygienic Design®, Narrow

Complementary products



HSS

Shoulder screw ISO7379, Hardened Steel class 12.9



SHSS

Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



SHW

Plain washer, A2 Stainless steel



SHN

Hexagonal nut DIN934, A2 Stainless steel