


Shoulder screw **stainless steel 416**

SHSS S/steel pre-treated 850-1000N/mm²

- **Material: pre-treated stainless steel 416**
26-32 HRC
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance 850-1000 N/mm²





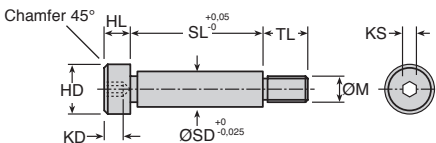

Uses

- For use in harsh environments



DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD		Price each	
	ØM	SD								1 to 5	
SHSS3-4	M3	3,987	4,013	6	3	4	2,0	1,6		15,01	€
SHSS3-5	M3	3,987	5,013	6	3	4	2,0	1,6		15,01	€
SHSS3-6	M3	3,987	6,013	6	3	4	2,0	1,6		15,01	€
SHSS3-8	M3	3,987	8,013	6	3	4	2,0	1,6		15,01	€
SHSS3-10	M3	3,987	10,013	6	3	4	2,0	1,6		15,01	€

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request


Part number	Thread				HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD	SL	HD						
SHSS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	-	15,01 €
SHSS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	-	15,01 €
SHSS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	21,34 €
SHSS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	-	22,88 €
SHSS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	22,88 €
SHSS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	37,36 €
SHSS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-20	M8	9,987	20,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	-	32,28 €
SHSS8-30	M10	9,987	30,013	14	7	12	6,0	4,0	-	27,98 €
SHSS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	33,93 €
SHSS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	-	On request

*Depending on availability - Dimensions in mm

Our other products



Accessories, Fixing kit

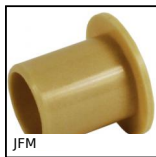

Flanged polymer bush, Universal polymer



Revolving handle for handwheel, Fixed



Right angle helical reducers, from 0.40 to 2.53 Nm



Speed controller 10A, 10 A



Right angle spiro bevel gearbox, Up to 78Nm



Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



Steel spur gear, Steel 20NCD2



Stainless steel diablo shaped elasto mount, Stainless steel



Castor for aluminium profile, With brake



60mm rubber wheel for conveyor belt, Rubber



Shaft for linear guides, Hardened ground stainless steel

Complementary products



Shoulder screw ISO7379, Hardened Steel class 12.9



Shoulder screw stainless steel 303, Stainless steel 303



Hexagonal nut DIN934, A2 Stainless steel



Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379