


Shoulder screw **stainless steel 416**

SHss S/steel pre-treated 850-1000N/mm²

- **Material: pre-treated stainless steel 416**
26-32 HRC
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance 850-1000 N/mm²





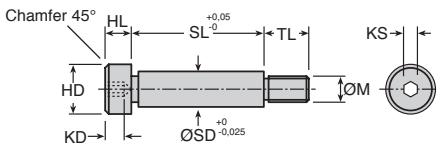

Uses

- For use in harsh environments



DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD		Price each	
	ØM	SD								1 to 5	6 to 10
SHSS3-4	M3	3,987	4,013	6	3	4	2,0	1,6		15,01	€
SHSS3-5	M3	3,987	5,013	6	3	4	2,0	1,6		15,01	€
SHSS3-6	M3	3,987	6,013	6	3	4	2,0	1,6		15,01	€
SHSS3-8	M3	3,987	8,013	6	3	4	2,0	1,6		15,01	€
SHSS3-10	M3	3,987	10,013	6	3	4	2,0	1,6		15,01	€

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread				HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD	SL	HD						
SHSS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	-	15,01 €
SHSS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	-	15,01 €
SHSS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	21,34 €
SHSS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	-	22,88 €
SHSS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	22,88 €
SHSS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	37,36 €
SHSS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-20	M8	9,987	20,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	-	32,28 €
SHSS8-30	M10	9,987	30,013	14	7	12	6,0	4,0	-	27,98 €
SHSS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	33,93 €
SHSS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	-	On request

*Depending on availability - Dimensions in mm

 
Our other products




RTTss
Locking assembly,
Medium/high torque



T5M T10M
T type timing belt per
metre, T5 Steel cored
polyurethane



 INO
Internal gear,
Machined plastic
(delrin)



BETASS
Hitch pin, Hitch



PSG3
Spur gear - precision
range, Pre-hardened
Steel 35NCD6



CAP805
Slot top chain
stainless steel, Large
range 805



DOMI80
Accessories, Fixing kit



RBNpl
Fixed castor with
plate, Steel - rubber



PTA50
Articulated levelling
foot, pressed base
Ø50, Ø 50



GFX
Curved tooth
coupling, economy
range, Steel and



SH0
Parallel axis helical
gear, Machined plastic
(delrin)



DOG11
Motor-gearbox 12V
and 24V DC, from 1.5
to 6 Nm

Complementary products



HSS
Shoulder screw
ISO7379, Hardened
Steel class 12.9



SHS
Shoulder screw
stainless steel 303,
Stainless steel 303



SHN
Hexagonal nut
DIN934, A2 Stainless
steel



HSSss
Stainless steel
shoulder screw
ISO7379, Stainless
steel ISO 7379