


Shoulder screw **stainless steel 416**

SHss S/steel pre-treated 850-1000N/mm²

- **Material: pre-treated stainless steel 416**
26-32 HRC
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance 850-1000 N/mm²





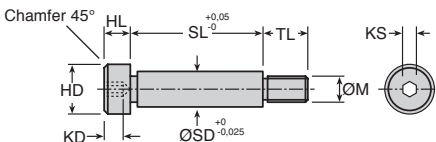

Uses

- For use in harsh environments



DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD		Price each	
	ØM	SD								1 to 5	
SHSS3-4	M3	3,987	4,013	6	3	4	2,0	1,6		15,01	€
SHSS3-5	M3	3,987	5,013	6	3	4	2,0	1,6		15,01	€
SHSS3-6	M3	3,987	6,013	6	3	4	2,0	1,6		15,01	€
SHSS3-8	M3	3,987	8,013	6	3	4	2,0	1,6		15,01	€
SHSS3-10	M3	3,987	10,013	6	3	4	2,0	1,6		15,01	€

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread				HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD	SL	HD						
SHSS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	-	15,01 €
SHSS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	-	15,01 €
SHSS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	21,34 €
SHSS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	-	22,88 €
SHSS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	22,88 €
SHSS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	37,36 €
SHSS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-20	M8	9,987	20,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	-	32,28 €
SHSS8-30	M10	9,987	30,013	14	7	12	6,0	4,0	-	27,98 €
SHSS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	33,93 €
SHSS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	-	On request

*Depending on availability - Dimensions in mm

Our other products



INS_SS
Self tapping stainless steel insert, 316 stainless steel



HSSss
Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



HTD14M_55
HTD Heavy duty timing pulley, HTD14 Cast



RBNpl
Swivel castor with plate, Steel - rubber



EPRC
High helix leadscrew, Cylindrical nut - up to 40mm per rotation



M1
Worm and wheel set, Non hardened steel



SLB
Indexing plunger, steel class 5.8



SBRtool
Chain tool, Drive chain maintenance tools



BLHM50
Right angled gearbox, double output shafts, up to 30 Nm



GB-RA
Brass spur gear, Brass CuZn39Pb3



WW16
Drylin® W slide, slide assembly



EHD04
Internal epicyclic servo reducers, from 3.4 to 7 Nm

Complementary products



HSS
Shoulder screw ISO7379, Hardened Steel class 12.9



SHS
Shoulder screw stainless steel 303, Stainless steel 303



SHN
Hexagonal nut DIN934, A2 Stainless steel



HSSss
Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379