


Shoulder screw **stainless steel 416**

SHSS S/steel pre-treated 850-1000N/mm²

- **Material: pre-treated stainless steel 416**
26-32 HRC
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance 850-1000 N/mm²





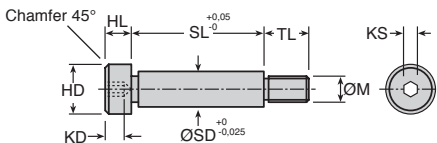

Uses

- For use in harsh environments



DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD		Price each	
	ØM	SD								1 to 5	
SHSS3-4	M3	3,987	4,013	6	3	4	2,0	1,6		15,01	€
SHSS3-5	M3	3,987	5,013	6	3	4	2,0	1,6		15,01	€
SHSS3-6	M3	3,987	6,013	6	3	4	2,0	1,6		15,01	€
SHSS3-8	M3	3,987	8,013	6	3	4	2,0	1,6		15,01	€
SHSS3-10	M3	3,987	10,013	6	3	4	2,0	1,6		15,01	€

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request


Part number	Thread				HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD	SL	HD						
SHSS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	-	15,01 €
SHSS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	-	15,01 €
SHSS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	21,34 €
SHSS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	-	22,88 €
SHSS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	22,88 €
SHSS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	37,36 €
SHSS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-20	M8	9,987	20,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	-	32,28 €
SHSS8-30	M10	9,987	30,013	14	7	12	6,0	4,0	-	27,98 €
SHSS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	33,93 €
SHSS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	-	On request

*Depending on availability - Dimensions in mm

Our other products



 PGB
Accessory-holder for aluminium profile,
Tool holder



INO
Internal gear,
Machined plastic
(delrin)



HTD14M_85
HTD Heavy duty
timing pulley, HTD14
Steel



SEH
Horizontal stirrup
toggle clamp,
Horizontal Latch
clamp - stainless ...



AC156-157
Strike for toggle latch,
25.5mm



BLH60
Right angled gearbox,
from 19 to 70 Nm




ACL-PLAngle
Joining plate for
aluminium profile,
Angle connection



SCE
U-shaped cable
clamp, Steel



 NPTF30
Spacer for tube
carrier, Fixing



PF30NM
Worm and wheel gear
reducer, up to 8.8 Nm



MSP38
Masterplate®
glueable insert Ø38,



AT5-BAR
AT type tooth bar
stock, AT5

Complementary products



HSS
Shoulder screw
ISO7379, Hardened
Steel class 12.9



SHS
Shoulder screw
stainless steel 303,
Stainless steel 303



SHN
Hexagonal nut
DIN934, A2 Stainless
steel



HSSss
Stainless steel
shoulder screw
ISO7379, Stainless
steel ISO 7379