


Shoulder screw **stainless steel 416**

SHss S/steel pre-treated 850-1000N/mm²

- **Material: pre-treated stainless steel 416**
26-32 HRC
- For centering as well as holding
- Working temperature up to +430°C
- Hexagonal socket head
- Traction resistance 850-1000 N/mm²





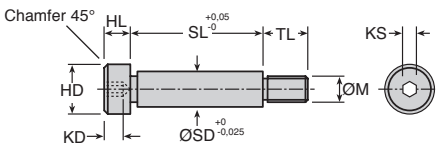

Uses

- For use in harsh environments



DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread		SL	HD	HL	TL	KS	KD		Price each	
	ØM	SD								1 to 5	
SHSS3-4	M3	3,987	4,013	6	3	4	2,0	1,6		15,01	€
SHSS3-5	M3	3,987	5,013	6	3	4	2,0	1,6		15,01	€
SHSS3-6	M3	3,987	6,013	6	3	4	2,0	1,6		15,01	€
SHSS3-8	M3	3,987	8,013	6	3	4	2,0	1,6		15,01	€
SHSS3-10	M3	3,987	10,013	6	3	4	2,0	1,6		15,01	€

*Depending on availability - Dimensions in mm

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+	300+
Disc.	List	-10%	-15%	-20%	-30%	-55%	On request

Part number	Thread				HL	TL	KS	KD	Stock*	Price each 1 to 5
	ØM	SD	SL	HD						
SHSS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	-	15,01 €
SHSS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	15,01 €
SHSS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	17,13 €
SHSS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	21,40 €
SHSS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	-	15,01 €
SHSS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	15,01 €
SHSS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	17,13 €
SHSS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	24,60 €
SHSS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	18,33 €
SHSS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	-	49,41 €
SHSS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	17,79 €
SHSS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	21,34 €
SHSS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	-	22,88 €
SHSS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	22,88 €
SHSS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	37,36 €
SHSS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-20	M8	9,987	20,013	14	7	12	5,0	4,0	✓	27,98 €
SHSS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	-	32,28 €
SHSS8-30	M10	9,987	30,013	14	7	12	6,0	4,0	-	27,98 €
SHSS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	33,93 €
SHSS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	28,16 €
SHSS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	-	On request

*Depending on availability - Dimensions in mm

Our other products



PGNT

Thermoplastic T handle, With threaded insert



EAR

Bearing locknut, Self locking locknut - nylon lock washer



CHAEss

Decorative hinge, Stainless steel



DB

Steel bevel gear, 2:1



RPC

Wheel, Polyamide



PM3

Worm and wheel set, Hardened steel




E60B

Right angle helical reducers, from 4.50 to 24 Nm



NT122

 Spur gear coaxial gearbox, from 32 to 85 Nm - In-line



PM2

Worm and wheel set, Machined plastic



RT70

Self-centering locking Assembly,



GE32

Sprung toggle latch with connecting link,



SCE

U-shaped cable clamp, Steel

Complementary products



HSS

Shoulder screw ISO7379, Hardened Steel class 12.9



SHS

Shoulder screw stainless steel 303, Stainless steel 303



SHN

Hexagonal nut DIN934, A2 Stainless steel



HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379