


Steel or stainless steel A2

**SHW
WM**

- **Conforms to DIN125**
- **Material:**
Zinc plated steel
Stainless steel A2 303/304
(working temperature:
up to +430°C)
- Sold by the packet

Option

- Also available in stainless steel 316 (A4)

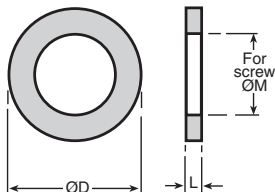

DISCOUNTS

N° packs	1+	6+	11+
Discounts	List	-10%	On request

Part number	For thread ØM	ØD	L	Quantity per packet	Stock*	Price each 1 to 5
Steel						
WM-2/B	M2	5	0,3	200	-	3,10 €
WM-2.5/B	M2,5	6	0,5	200	-	2,33 €
WM-3/B	M3	7	0,5	200	-	2,48 €
WM-4/B	M4	9	0,8	200	✓	2,82 €
WM-5/B	M5	10	1,0	100	-	2,33 €
WM-6/B	M6	12	1,6	100	-	2,75 €
WM-8/B	M8	16	1,6	100	✓	3,30 €
WM-10/B	M10	20	2,0	100	✓	4,65 €
WM-12/B	M12	24	2,5	100	-	7,41 €
WM-14/B	M14	28	2,5	100	-	9,06 €
WM-16/B	M16	30	3,0	100	-	13,97 €
WM-20/B	M20	37	3,0	100	-	15,79 €
Stainless steel A2						
SHW-2/B	M2	5	0,3	2000	✓	10,37 €
SHW-2.5/B	M2,5	6	0,5	2000	✓	17,35 €
SHW-3/B	M3	7	0,5	1000	✓	2,73 €
SHW-4/B	M4	9	0,8	1000	✓	5,51 €
SHW-5/B	M5	10	1,0	1000	✓	7,59 €
SHW-6/B	M6	12	1,6	1000	✓	18,00 €
SHW-8/B	M8	16	1,6	500	✓	12,24 €
SHW-10/B	M10	20	2,0	500	✓	30,15 €
SHW-12/B	M12	24	2,5	200	✓	25,64 €
SHW-14/B	M14	28	2,5	200	✓	30,91 €
SHW-16/B	M16	30	3,0	200	✓	31,60 €
SHW-20/B	M20	37	3,0	200	✓	43,28 €

*Depending on availability - Dimensions in mm

Our other products



VQT

Quarter-turn clamp lock, Plastic or stainless steel button



VDS

Sliding lock adjustment system, Sliding lock for oblong hole



DIA

Ring operated locking bolt, with ring



PRF-SCL

Lock for aluminium profile, Lock for sliding doors



RHTplss

High Temperature Castor, up to 200kg



CHAE6555

Decorative screwed hinge, Aluminium



KK

Rounded end feather key, Steel



HTD14M_85

HTD Heavy duty timing pulley, HTD14 Cast



TCXR

Automatic chain tensioner, With steel sprocket



DHX

Dowel pin internal thread, Extractable DIN 7979D



SH2

Parallel axis helical gear, Steel 20NCD2



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps

Complementary products



SHWbr

Washer - DIN125, Brass



SHN

Hexagonal nut DIN934, A2 Stainless steel



NIN

Self-locking nut, A2 Stainless steel



TIF

Threaded rod - DIN975, Stainless steel A2