


Steel or stainless steel A2

**SHW  
WM**

- **Conforms to DIN125**
- **Material:**  
Zinc plated steel  
Stainless steel A2 303/304  
(working temperature:  
up to +430°C)
- Sold by the packet

### Option

- Also available in stainless steel 316 (A4)

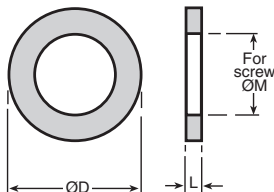

### DISCOUNTS

N° packs	1+	6+	11+
Discounts	List	-10%	On request

Part number	For thread ØM	ØD	L	Quantity per packet	Stock*	Price each 1 to 5
<b>Steel</b>						
WM-2/B	M2	5	0,3	200	-	3,10 €
WM-2.5/B	M2,5	6	0,5	200	-	2,33 €
WM-3/B	M3	7	0,5	200	-	2,48 €
WM-4/B	M4	9	0,8	200	✓	2,82 €
WM-5/B	M5	10	1,0	100	-	2,33 €
WM-6/B	M6	12	1,6	100	-	2,75 €
WM-8/B	M8	16	1,6	100	✓	3,30 €
WM-10/B	M10	20	2,0	100	✓	4,65 €
WM-12/B	M12	24	2,5	100	-	7,41 €
WM-14/B	M14	28	2,5	100	-	9,06 €
WM-16/B	M16	30	3,0	100	-	13,97 €
WM-20/B	M20	37	3,0	100	-	15,79 €
<b>Stainless steel A2</b>						
SHW-2/B	M2	5	0,3	2000	✓	10,37 €
SHW-2.5/B	M2,5	6	0,5	2000	✓	17,35 €
SHW-3/B	M3	7	0,5	1000	✓	2,73 €
SHW-4/B	M4	9	0,8	1000	✓	5,51 €
SHW-5/B	M5	10	1,0	1000	✓	7,59 €
SHW-6/B	M6	12	1,6	1000	✓	18,00 €
SHW-8/B	M8	16	1,6	500	✓	12,24 €
SHW-10/B	M10	20	2,0	500	✓	30,15 €
SHW-12/B	M12	24	2,5	200	✓	25,64 €
SHW-14/B	M14	28	2,5	200	✓	30,91 €
SHW-16/B	M16	30	3,0	200	✓	31,60 €
SHW-20/B	M20	37	3,0	200	✓	43,28 €

\*Depending on availability - Dimensions in mm

## Our other products



SBF

Sealed flange bearing unit for Food Industry, cover



T25-6ECO

T type timing pulley, Economy range - T2.5 aluminium



 
SER

Magnetic doorstop for aluminium profile, Magnetic doorstop



BSP

Compact precision slide, from 156 N to 980 N



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools



BPL

Ball transfer unit light duty, Light



TB8

Cylindrical roller thrust bearing, Steel



HD

Double needle roller universal joint, Heavy duty



DOMI30

Accessories, Plate




BLHM60

Right angled gearbox, double output shafts,



BLHT30

 Right angled gearbox, from 1.65 to 4.40 Nm



GMK17\_P

Flat Guide, Flat guide for conical profile

## Complementary products



SHS

Shoulder screw stainless steel 303, Stainless steel 303



TIF

Threaded rod - DIN975, Stainless steel A2



SHN

Hexagonal nut DIN934, A2 Stainless steel



NIN

Self-locking nut, A2 Stainless steel