

Steel or stainless steel A2

SHW
WM


- **Conforms to DIN125**
- Working temperature:
up to +430°C
- Material:
Stainless steel A2
303/304
- Sold by the packet

Accessories

- Steel and stainless steel screws

Option

- Also available in stainless steel 316 (A4)

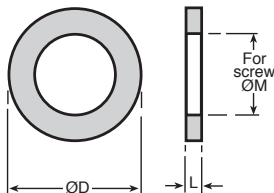

Steel or stainless steel

DISCOUNTS

N° packs	1+	6+	11+
Discounts	List	-10%	On request

Part number	For thread ØM	ØD	L	Quantity per packet	Stock*	Price each 1 to 5
Steel						
WM-2/B	M2	5	0,3	200	-	3,10 €
WM-2.5/B	M2,5	6	0,5	200	-	2,33 €
WM-3/B	M3	7	0,5	200	-	2,48 €
WM-4/B	M4	9	0,8	200	✓	2,82 €
WM-5/B	M5	10	1,0	100	-	2,33 €
WM-6/B	M6	12	1,6	100	-	2,75 €
WM-8/B	M8	16	1,6	100	✓	3,30 €
WM-10/B	M10	20	2,0	100	✓	4,65 €
WM-12/B	M12	24	2,5	100	-	7,41 €
WM-14/B	M14	28	2,5	100	-	9,06 €
WM-16/B	M16	30	3,0	100	-	13,97 €
WM-20/B	M20	37	3,0	100	-	15,79 €
Stainless steel A2						
SHW-2/B	M2	5	0,3	2000	✓	10,53 €
SHW-2.5/B	M2,5	6	0,5	2000	✓	17,60 €
SHW-3/B	M3	7	0,5	1000	✓	2,76 €
SHW-4/B	M4	9	0,8	1000	✓	5,59 €
SHW-5/B	M5	10	1,0	1000	✓	7,70 €
SHW-6/B	M6	12	1,6	1000	✓	18,27 €
SHW-8/B	M8	16	1,6	500	✓	12,41 €
SHW-10/B	M10	20	2,0	500	✓	30,59 €
SHW-12/B	M12	24	2,5	200	✓	26,01 €
SHW-14/B	M14	28	2,5	200	✓	31,37 €
SHW-16/B	M16	30	3,0	200	✓	32,07 €
SHW-20/B	M20	37	3,0	200	✓	43,93 €

*Depending on availability - Dimensions in mm

Our other products



GAC
Latch clamp with lock,
Lockable



GCB882
Curved track, Range
882




SSB
Stainless steel bevel
gear, 1:1



MRA
Quick link, Steel



 
PXHG15
Crossed helical gear -
precision range,
35NCD6 Pre-hardened
steel



T5courroie
Closed belt, T5 Steel
cored polyurethane



 ARL_SRS
Plastic flexible rack,
Rack clamp




B
Bevel gear - Steel
60C40, 1:1



PRF_PF
Floor anchor, Anchor



 BPH
Ball transfer unit, High




RPPM
RPP type belt by the
metre, RPP14 Steel
cored polyurethane



NIN
Self locking nut - DIN
985, Steel

 Complementary products



RAP
Captive washer, Nylon



SHN
Six-sided nut - DIN
934, A2 Stainless
steel



TIF
Threaded rod - DIN
975, Stainless steel
A2



SHS
Shoulder screw,
Stainless steel 303