

Toggle clamps



Round faced nut

SLH-M

- Nut for toggle clamps
- Material : steel
- Finish : oxidised

Advantage

- Nut can be welded in place

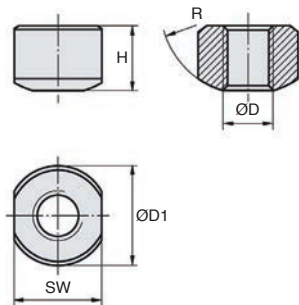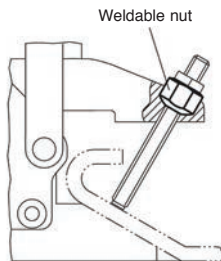

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	ØD	H	ØD1	SW	R	Price each 1 to 5
SLH-M4	M4	5,2	8	7	7	2,57 €
SLH-M5	M5	6,7	10	9	9	2,70 €
SLH-M6	M6	9,5	13,5	12,2	10	2,96 €
SLH-M8	M8	12,8	18	15,3	12	3,61 €
SLH-M10	M10	12,1	20	18,2	14	3,87 €
SLH-M12	M12	14,8	23	20	16	4,20 €

Dimensions in mm

Our other products



PR882
Idler sprocket for slat top chain, Range 882



TBD
Manual leadscrew table with opposing threads, 5kg



DPAK_DKON
Conical elasto buffer, Steel




MPE
Hexagonal spacer, Steel



MAX22
Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



 GBSz
Cylindrical ballscrew nut, Cylindrical leadscrew nut



GLT2-27
Telescopic drawer runners for groove mounting, Partial extension



NTMdI
Set screw delrin tip, Delrin-point



DILC
Indexing plunger with cam, with cam



PRF-SRA
Lock for aluminium profile, Lock



STRIP
Sealing brush strip, 1m length



RBNpl
Swivel castor with plate, Steel - rubber

Complementary products



SLHHlok
Horizontal toggle clamp, Horizontal toggle clamp / horizontal foot



SLHVlok
Horizontal toggle clamp, Horizontal toggle clamp / vertical foot