

Toggle clamps

Round faced nut

SLH-M



- Nut for toggle clamps

- Material : steel

- Finish : oxidised

Advantage

- Nut can be welded in place

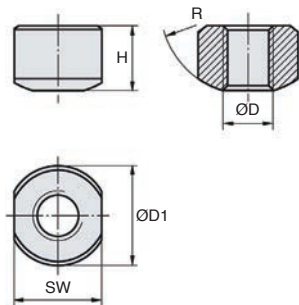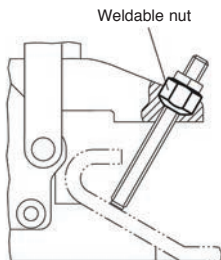

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	ØD	H	ØD1	SW	R	Price each 1 to 5
SLH-M4	M4	5,2	8	7	7	2,57 €
SLH-M5	M5	6,7	10	9	9	2,70 €
SLH-M6	M6	9,5	13,5	12,2	10	2,96 €
SLH-M8	M8	12,8	18	15,3	12	3,61 €
SLH-M10	M10	12,1	20	18,2	14	3,87 €
SLH-M12	M12	14,8	23	20	16	4,20 €

Dimensions in mm

Our other products



SLB

Indexing plunger,
steel class 5.8



D19 D29

Compression springs
in metre length steel,
by the metre



PW_PWG3

Worm - precision
range, Stainless steel



CHAR16046

Spring hinge, screwed



HRV

V- rail guidance
Simple Select®
system, Rail with
carriage




BABTV

Ball lock pins lockable
, Stainless steel



CPAS

Stay with safety
catch, Opens upward

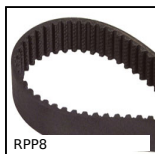

RPP8

RPP heavy duty
timing belt, RPP8



 
SSE

Stainless steel
spherical bearing,
Stainless steel / PTFE



RBNpl

Fixed castor with
plate, Steel - rubber



QNU

 
Single row cylindrical
roller bearing, Free
inner ring



JCDss

Double universal joint
- Stainless steel, Low
duty

Complementary products



SLHHlok

Horizontal toggle clamp,
Horizontal toggle clamp /
horizontal foot



SLHVlok

Horizontal toggle clamp,
Horizontal toggle clamp /
vertical foot