

# Horizontal toggle clamp





## SLH

## Secures by direct pressure

- Materials:
  - Body: zinc plated steel
  - Fastening pin and nuts: phosphated steel
  - Handle: Oil resistant plastic
- With fixing base and adjustable fastening pin

### Options

- Mounting bracket (please ask us)

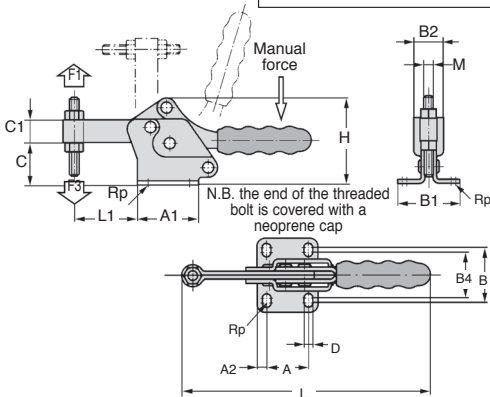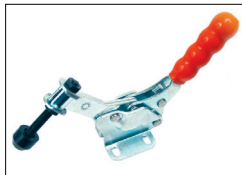

### DISCOUNTS

Qty.	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	Opening angle of securing arm Pos. 1	Opening angle of handle Pos. 1	Manual force (N)	Manual force F1(N)	Securing force F3(N)
SLH-0075	90°	75°	80	750	320
SLH-0150	90°	80°	140	1500	650

Part number	A	A1	A2	B	B1	B2	B4	C	C1	D	H	L	L1	M	Stock*	Price each 1 to 5
SLH-0075	13,5	25	5,7	16,8	27	16	-	19	9,5	5,2	38	108	24,5	M5x35	✓	23,12 €
SLH-0150	26,0	38	6,0	28,0	40	20	22	25	14,0	5,5	53	155	38,0	M6x50	✓	27,24 €

\*Subject to availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products




PARF80  
Pressed steel base  
rigid foot, Swivelling -  
Ø80



ZG1  
Plastic spur gear,  
Machined plastic  
(delrin)



 HRV  
V- rail guidance  
Simple Select®  
system, Rail with  
carriage



BLHM60  
Right angled gearbox,  
double output shafts,  
up to 70 Nm



PMC150\_M16  
Anti-vibration  
machine mount,  
Square base plate



JCDss  
Double universal joint  
- Stainless steel, Low  
duty



CSSSS  
Stainless steel  
spherical bearing,  
Stainless steel / PTFE



CLG2  
Moulded plastic spur  
gear, Moulded plastic  
(nylon)



ZG1  
Plastic spur gear,  
Machined plastic



EFTC  
Fixing support,  
Stainless steel



PPF  
Indexing plunger with  
flange, with drilled



CMA  
Eye bolt, Steel

## Complementary products



SLHHlok  
Horizontal toggle  
clamp, Horizontal  
toggle clamp /  
horizontal foot