

Horizontal toggle clamp





SLH

Secures by direct pressure

- Materials:
 - Body: zinc plated steel
 - Fastening pin and nuts: phosphated steel
 - Handle: Oil resistant plastic
- With fixing base and adjustable fastening pin

Options

- Mounting bracket (please ask us)

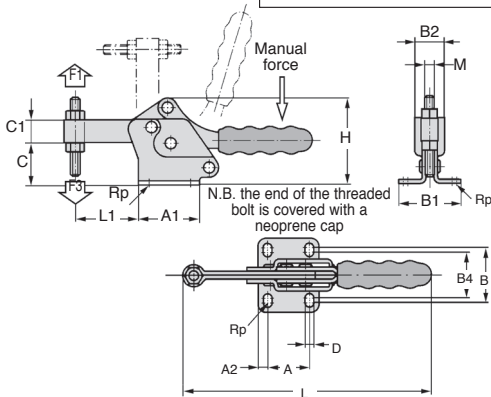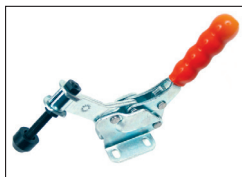

DISCOUNTS

Qty.	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	Opening angle of securing arm Pos. 1	Opening angle of handle Pos. 1	Manual force (N)	Manual force F1(N)	Securing force F3(N)
SLH-0075	90°	75°	80	750	320
SLH-0150	90°	80°	140	1500	650

Part number	A	A1	A2	B	B1	B2	B4	C	C1	D	H	L	L1	M	Stock*	Price each 1 to 5
SLH-0075	13,5	25	5,7	16,8	27	16	-	19	9,5	5,2	38	108	24,5	M5x35	✓	23,12 €
SLH-0150	26,0	38	6,0	28,0	40	20	22	25	14,0	5,5	53	155	38,0	M6x50	✓	27,24 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CHM30

Worm and wheel gear reducer, up to 28 Nm



NSO

Housing for open linear bearing, Opened - long



AC

Strike for toggle latch, 12,13,18 and 20mm



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



RHTplss

High Temperature Castor, up to 200kg



LBE

Miniature closed linear bearing, Miniature



SHO

Parallel axis helical gear, Machined plastic (delrin)



INS

Self tapping steel insert, Steel



WS20

Drylin® W rail, Rail



DGSA

Male rod ends, Steel / steel - Economy range



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2



VTHA

Magnetic screw with hexagonal head, Steel

Complementary products



SLHHlok

Horizontal toggle clamp, Horizontal toggle clamp / horizontal foot