

Vertical toggle clamp

With **locking mechanism**

SLVVLOK

High quality swivel bush with vertical foot and adjustable spindle


 


Constant level of force during both opening and closing
Increased stability thanks to U-shaped clamping arm
Fitted with automatic locking mechanism

- Material :


Nitro carburised steel with blackened finish

Polyamide handle

Locking mechanism TPE

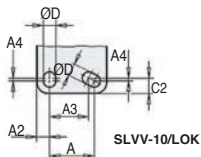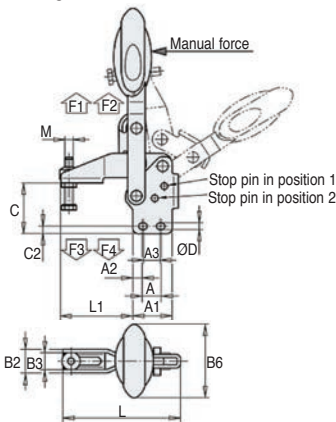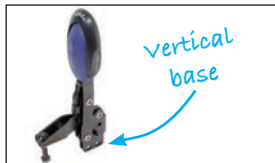

Hole positions

 

Hole positions

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	Opening angle (Holding arm)			Opening angle (Handle)			Manual force N	Holding force		Clamping force	
	Pos. 1	Pos. 2	Stop pin removed	Pos. 1	Pos. 2	F1 (N)		F2 (N)	F3 (N)	F4 (N)	
SLVV-6/LOK	56°	83°	156°	46°	56°	160	1350	1650	920	1050	
SLVV-8/LOK	13°	93°	157°	26°	61°	190	2000	2800	940	1350	
SLVV-10/LOK	6°	97°	175°	19°	59°	250	2500	4500	1500	2800	
SLVV-12/LOK	11°	88°	163°	24°	60°	280	3000	5500	1400	2800	

Part number	M	A	A1	A2	A3	A4	B	B1	B2	B3	B6	C	C2	OD	H	L	L1	Price each 1 to 5
SLVV-6/LOK	M6x35	14	29	7	12	-	10,2	5,2	17,5	12,4	53,4	37,6	5,5	5,5	175,7	86,5	53	49,82 €
SLVV-8/LOK	M8x45	21	39	9	19	-	10,2	5,2	20,6	15,5	51,1	49	6,5	6,8	207,6	107	62	55,97 €
SLVV-10/LOK	M10x55	32	50	8	27	3,5	14,1	7,1	25,5	18,4	56,5	62,3	13	9	254	153	95	76,65 €
SLVV-12/LOK	M12x70	32	53	10,5	-	-	14,1	7,1	28	20,9	56,5	69,8	9	8,8	271,9	173,5	113,5	79,23 €

Dimensions in mm

Our other products



VHEH

Hexagonal headed screw with collar
Hygienic Usit®,
Stainless steel



PCLA_T

Technopolymer
clamping lever - male,
Plastic



RPCtc

Swivel castor with
central hole, Steel -
Polyamide - with
double brake



PRF_T

Corner reinforcement,
Corner reinforcement



ETQ

Magnetic label holder for
aluminium profile,
Label holder



HCSS

Set screw with
hexagonal socket,
Cup point



ACLBMC

Detector support for
aluminium profile,
Sensor holder



HW_HT

Half-rail guide, Rail



ACLALF

Adjustable foot for
aluminium profile,



CHC

Socket headed screw,
Steel class 12.19



HDSS

Needle roller double
universal joint -



BAN

 
Angular clamp,
Standard

Complementary products



SLH-M

Nut for toggle clamp,
Round ended nut for
SLH/SLV clamp



SLVHlok

Vertical toggle clamp,
Vertical toggle clamp /
horizontal foot