

Vertical toggle clamp

With **locking mechanism**

SLVVLOK

High quality swivel bush with vertical foot and adjustable spindle


 

Constant level of force during both opening and closing
Increased stability thanks to U-shaped clamping arm
Fitted with automatic locking mechanism

- Material :


Nitro carburised steel with blackened finish

Polyamide handle

Locking mechanism TPE

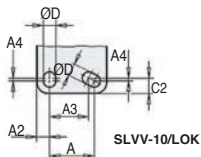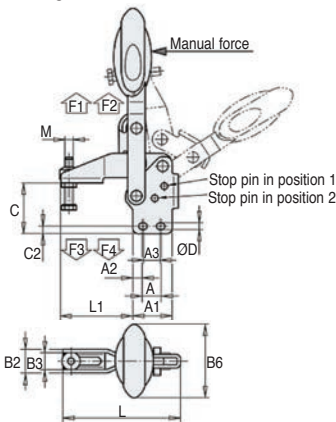

Hole positions

 

Hole positions

DISCOUNTS


Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	Opening angle (Holding arm)			Opening angle (Handle)			Manual force N	Holding force		Clamping force	
	Pos. 1	Pos. 2	Stop pin removed	Pos. 1	Pos. 2	F1 (N)		F2 (N)	F3 (N)	F4 (N)	
SLVV-6/LOK	56°	83°	156°	46°	56°	160	1350	1650	920	1050	
SLVV-8/LOK	13°	93°	157°	26°	61°	190	2000	2800	940	1350	
SLVV-10/LOK	6°	97°	175°	19°	59°	250	2500	4500	1500	2800	
SLVV-12/LOK	11°	88°	163°	24°	60°	280	3000	5500	1400	2800	

Part number	M	A	A1	A2	A3	A4	B	B1	B2	B3	B6	C	C2	OD	H	L	L1	Price each 1 to 5
SLVV-6/LOK	M6x35	14	29	7	12	-	10,2	5,2	17,5	12,4	53,4	37,6	5,5	5,5	175,7	86,5	53	49,82 €
SLVV-8/LOK	M8x45	21	39	9	19	-	10,2	5,2	20,6	15,5	51,1	49	6,5	6,8	207,6	107	62	55,97 €
SLVV-10/LOK	M10x55	32	50	8	27	3,5	14,1	7,1	25,5	18,4	56,5	62,3	13	9	254	153	95	76,65 €
SLVV-12/LOK	M12x70	32	53	10,5	-	-	14,1	7,1	28	20,9	56,5	69,8	9	8,8	271,9	173,5	113,5	79,23 €

Dimensions in mm

 Our other products




LAT1

1A motorised linear actuator, 1 ampere



GLT2-17

 Telescopic drawer runners for groove mounting, Partial extension



M1

Worm and wheel set, Bronze



PRF-GUM

Aluminium profile anodising polisher, Polishing block



RFK28B

Hypoid gearbox - Stainless steel, up to 130 Nm



NSU

Universal 90° support clamp, Universal 90° support clamp



ACLBMC

Detector support for aluminium profile, Sensor holder



LVT

Miniature motorised actuator 1A, 1 ampere



CLAT

Clamping lever Hygienic Usit® - male, Stainless steel



RURt

Swivel castor with central hole, Polyurethane -



HTD8M_30

HTD Heavy duty timing pulley, HTD8 Cast



PSG08

Spur gear - precision range, Pre-hardened Steel 35NCD6

Complementary products



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot