

# Floor mounting levelling plate



## SPIT

## Maximum load 40.000N

- Levelling support for attaching to a floor

- Materials:

Base: galvanised steel





Rod: galvanised steel (nut not supplied)

### Advantages

- Capable of accepting heavy loads.

### Option

- In stainless steel or other dimension if important quantity

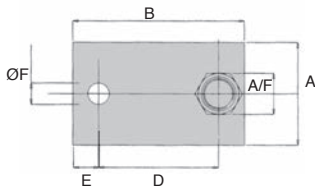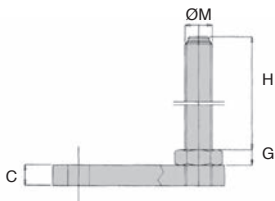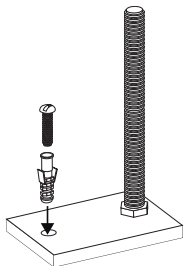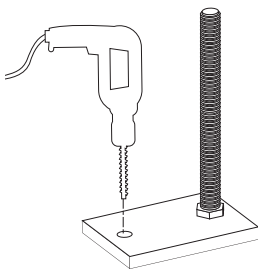


### DISCOUNTS

Qty	1+	25+	50+
Disc.	List	-5%	On request

Part number	A	B	C	ØM	H	D	E	ØF	G	A/F	Max. load(N)	Price each
SPIT16-150	60	100	12	M16	150	70	15	18	9	24	30000	✓ 23,71 €
SPIT20-200	80	110	12	M20	200	80	15	18	9	24	40000	✓ 26,49 €

\*Depending on availability - Dimensions in mm

 
## Our other products



PRF PSP\_PR  
Dual purpose strip  
and cover for  
aluminium profile,  
Inserts into slot



 BPHF  
Ball transfer unit push  
fit, Heavy



TBV  
Manual lifting tables,  
12kg



HSE-HSB  
Hexagonal spacer,  
Steel



HTD8M\_50  
HTD Heavy duty  
timing pulley, HTD8  
Cast



NRV  
Orthogonal support  
clamp, Orthogonal  
support clamp



UGPC  
Actuator guide kit,  
Short bearing



HTD8M\_30  
HTD Heavy duty  
timing pulley, HTD8  
Steel



BOX-NINA  
Self locking nut -  
DIN985, Box set of  
steel nuts



RAGFLOWsupport  
Floway2® Roller track  
accessory, Roller  
track support



BOX-TOR-DRING  
Box set of Nitrile D-  
rings NBR90Sh A,  
Flange seals



UTKpwcr  
Utilitrak® 3 wheels  
carriage, Polymer  
roller carriage

## Complementary products



PARF80  
Pressed steel base  
rigid foot, Swivelling -  
Ø80



PARF110  
Pressed steel base  
rigid foot, Swivelling  
Ø110