

Floor mounting levelling plate



SPIT

Maximum load 40.000N

- Levelling support for attaching to a floor

- Materials:

Base: galvanised steel





Rod: galvanised steel (nut not supplied)

Advantages

- Capable of accepting heavy loads.

Option

- In stainless steel or other dimension if important quantity

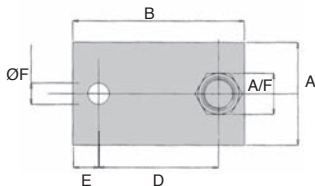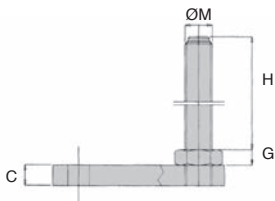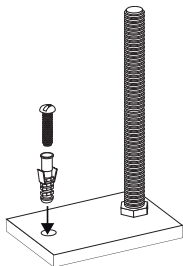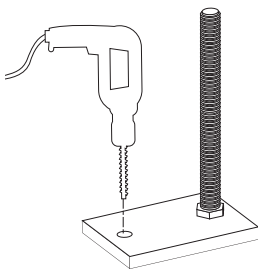

DISCOUNTS

Qty	1+	25+	50+
Disc.	List	-5%	On request

Part number	A	B	C	ØM	H	D	E	ØF	G	A/F	Max. load(N)	Stock*	Price each 1 to 24
SPIT16-150	60	100	12	M16	150	70	15	18	9	24	30000	✓	23,71 €
SPIT20-200	80	110	12	M20	200	80	15	18	9	24	40000	✓	26,49 €

*Depending on availability - Dimensions in mm

Our other products



PGM86-M5
Pull handle,
Thermoplastic



BAC105
Storage bin, 8mm



MSP38
Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
threaded s...



ABL100000
Antistatic brush, For
sensitive surfaces



MSP19
Masterplate®
glueable insert Ø19,
Cylindrical with
tapped insert



GAL48_OMNI
Omni-directional
roller, Omni-
directional



 
PCP
Cell carrier assembly,
Ready assembled



PAM_SS
Stainless steel
articulated levelling
foot, Ø30 & 40



RJA11_27
Sealing strip, Not
clipping



RPP8
RPP heavy duty
timing belt, RPP8



E30
Right angle helical
reducers, from 1.50 to
9 Nm



GCB880
Curved track for slat
top chain, Ranges 880
and 881

Complementary products



PARF80
Pressed steel base
rigid foot, Swivelling -
Ø80



PARF110
Pressed steel base
rigid foot, Swivelling
Ø110