 



- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:  
Stainless steel 304L except  
module 0.25: stainless steel 303

### Option

- Alternative lengths available

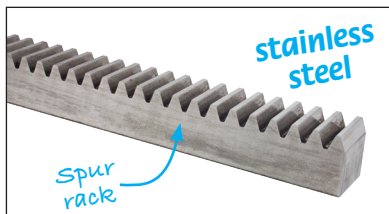

### DISCOUNTS

Qty	1+	3+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Module	P	W	H	L	Stock*	Price each 1 to 2
SR0.5-400/304L	0,50	11,50	6,00	12	400	✓	96,77 €
SR0.8-400/304L	0,80	11,20	6,00	12	400	✓	102,46 €
SR1-400/304L	1,00	14,00	8,00	15	400	✓	108,16 €

Depending of availability - Dimensions in mm

## Our other products



ACLERP

Roller block for aluminium profile, Without guide rail



PNA\_R

PERIFLEX elastic coupling, Replacement tyre



G0

Steel spur gear, Steel 20NCD2



VT

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



E60

Right angle helical reducers, from 4.50 to 62 Nm



CHT

Asynchronous AC Motor 1.1 to 1.85kW, 1.1 to 1.85kW



HW\_HT

Half-rail guide, Rail



 
BOX-TOR-C

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



DILC

Indexing plunger with cam, with cam



MRS

Stainless steel metric section rack, Stainless



SCA

Flat cable clamp, Steel



PCS25ECO

Chain sprocket - steel, 6.35mm

## Complementary products



R\_RR

Narrow spur rack, Steel



SSG1\_304L

Stainless steel spur gear, Stainless steel 304L