 



- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
Stainless steel 304L except
module 0.25: stainless steel 303

Option

- Alternative lengths available

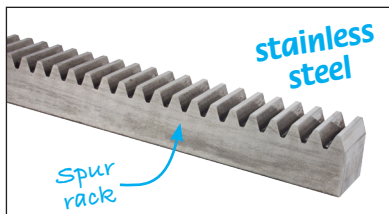

DISCOUNTS

Qty	1+	3+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Module	P	W	H	L	Stock*	Price each 1 to 2
SR0.5-400/304L	0,50	11,50	6,00	12	400	✓	96,77 €
SR0.8-400/304L	0,80	11,20	6,00	12	400	✓	102,46 €
SR1-400/304L	1,00	14,00	8,00	15	400	✓	108,16 €

Depending of availability - Dimensions in mm

Our other products




PFL

P-FLEX Coupling, Set screw



UTKpwr

Utilitak® V rail, V rail

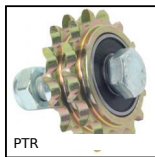

PTR

Idler chain sprocket,
For standard applications



RBNpl

Swivel castor with
double brake, Steel -
rubber



GET-AL

Jaw coupling,
economy range,
Aluminium



ACLBMC

Detector support for
aluminium profile,
Sensor holder



YGO

HEAVY DUTY spur
gear, Steel 35NCD6



PCS62

Chain sprocket - steel,
15.875 (DIN 10B-1)



AC144

Strike for toggle latch,
22mm



F7-SF-SM

Multifunction display,
Right angled
mounting bracket



VLBG

Lifting ring, Rotating



WJRM

Drylin® W hybrid
bearing block, Hybrid
bearings

Complementary products



R_RR

Narrow spur rack,
Steel



SSG1_304L

Stainless steel spur
gear, Stainless steel
304L