 
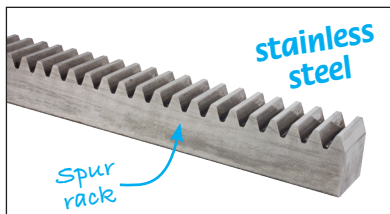


- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
Stainless steel 304L except
module 0.25: stainless steel 303

Option

- Alternative lengths available

**DISCOUNTS**

Qty	1+	3+	6+	10+
Disc.	List	-10%	-15%	On request

Part number	Module	P	W	H	L	Stock*	Price each 1 to 2
SR0.5-400/304L	0,50	11,50	6,00	12	400	✓	96,77 €
SR0.8-400/304L	0,80	11,20	6,00	12	400	✓	102,46 €
SR1-400/304L	1,00	14,00	8,00	15	400	✓	108,16 €

Depending of availability - Dimensions in mm

Our other products



TCL
T-Clip - Aluminium profile attachment, T-Clip



MDB_MTB
Moulded plastic bevel gear (nylon), 3:1



PTA80
Articulated levelling foot, pressed base Ø80, Ø 80



ASM
Cylindrical polymer bush, Food grade polymer



LRM
Trapezoidal bronze nut, Bronze - 1 thread



RFVcap
Stainless steel protective cover, Open protective cover



DOMI120
Connecting kits, XZ linking kit



DIA
Ring operated locking bolt, with ring



ACLERP
Roller block for aluminium profile, With guide rail



KKB-AR
Linear bearing with inclined ball tracks, Standard loads / -20°



SUA4
Single chain supplied by the metre, Steel



PTAF100-PAMF100
Articulated fixable foot with pressed base Ø100, Ø 100

Complementary products



R_RR
Narrow spur rack, Steel



SSG1_304L
Stainless steel spur gear, Stainless steel 304L