

# Adjustable latch clamp with catch plate **SteSta**

## SRG20 Span adjustable from 77.3 to 83mm

### - Adjustable latch clamp with catch-plate


#### - Materials:

- Chromed steel
- Non treated 304 stainless steel



### Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

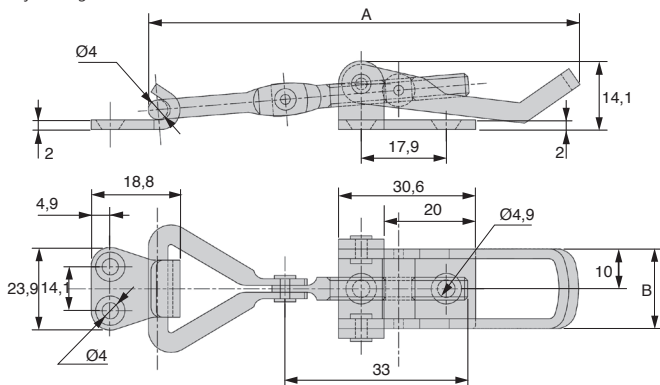

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	Material	Finish	Weight(g)	Stock*	Price each 1 to 9
SRG40-117-128	117,4 to 128	40,6	Steel	Galvanised	130	✓	8,03 €
SRG40-117-128/SS	117,4 to 128	40,6	S-Steel 304	Natural	130	✓	26,32 €

\*Subject to availability - Dimensions in mm

# SteSta Adjustable latch clamp with catch plate


Span adjustable from 96 to 121.7mm SRG25

## - Adjustable latch clamp with catch-plate

- Materials:  
Chromed steel  
Non treated 304  
stainless steel

## Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

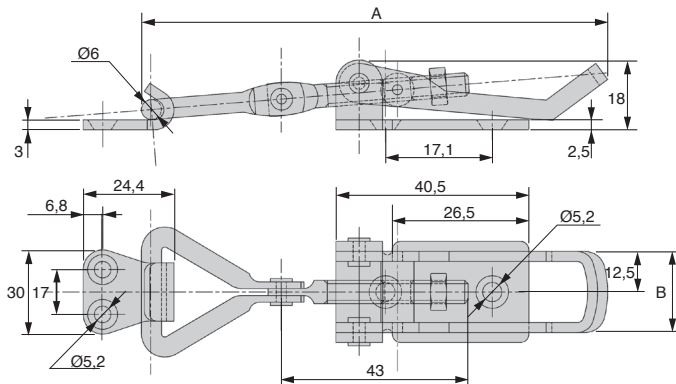

## DISCOUNTS

Qty	1+	10+	20+	50+
Disc. List	-3%	-5%	On request	

Part number	X	A	B	Material	Finish	Weight(g)	Stock*	Price each 1 to 9
SRG52-78-90	78 to 90	67	52	Steel	Galvanised	100	✓	15,11 €
SRG52-78-90/SS	78 to 90	67	52	S-Steel 304	Natural	100	✓	29,53 €

\*Subject to availability - Dimensions in mm

# Adjustable latch clamp with catch plate **Ste|Sta**

## SRG40 Span adjustable from 117.4 to 128mm


### - Adjustable latch clamp with catch-plate

#### - Materials:

- Chromed steel
- Non treated 304 stainless steel

### Application

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

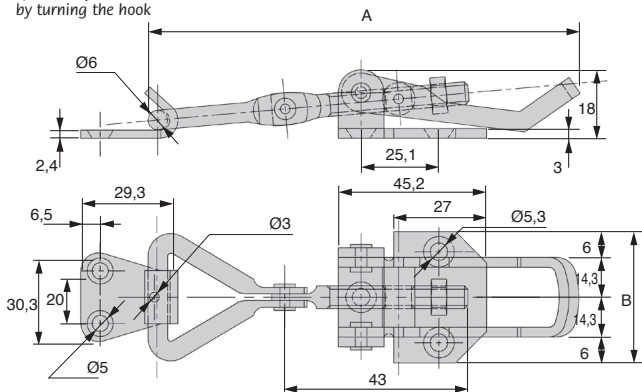

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-3%	-5%	On request

Part number	A	B	Material	Finish	Weight(g)	Stock*	Price each 1 to 9
SRG40-117-128	117,4 to 128	40,6	Steel	Galvanised	130	✓	8,03 €
SRG40-117-128/SS	117,4 to 128	40,6	S-Steel 304	Natural	130	✓	26,32 €

\*Subject to availability - Dimensions in mm

# SteSta Adjustable latch clamp with catch plate



Span adjustable from 78 to 90mm **SRG52**

**- Adjustable latch clamp with catch-plate**

- Materials:  
Chromed steel  
Non treated 304 stainless steel

**Application**

- Clamping system for industrial applications
- Fold down the handle after attaching the hook
- Span is adjusted by turning the hook

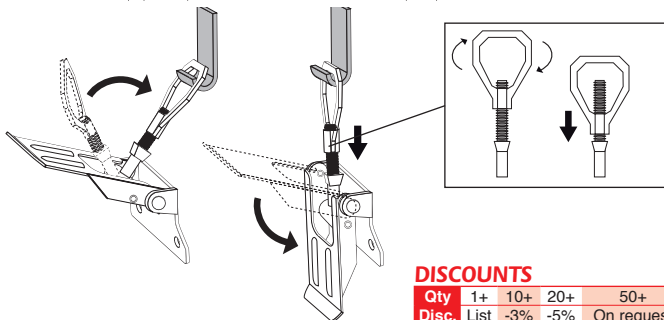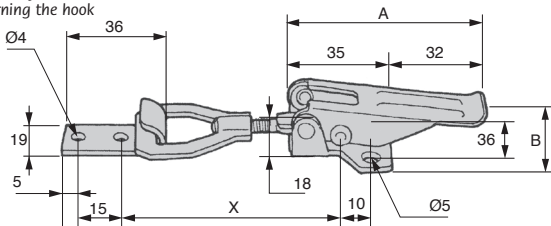

**DISCOUNTS**

<b>Qty</b>	1+	10+	20+	50+
<b>Disc. List</b>	-3%	-5%	On request	

Part number	X	A	B	Material	Finish	Weight(g)	Stock*	Price each 1 to 9
SRG52-78-90	78 to 90	67	52	Steel	Galvanised	100	✓	15,11 €
SRG52-78-90/SS	78 to 90	67	52	S-Steel 304	Natural	100	✓	29,53 €

\*Subject to availability - Dimensions in mm

## Our other products



CHA1056\_U4

Screw-in hinge,  
Section 40X40



BOXINS300

Box set of self tapping  
inserts, Boxed set -  
For hard materials



LBE

Miniature closed  
linear bearing,  
Miniature



CHMR110

Worm and wheel gear  
reducer, up to 980  
Nm



 
SBS\_L

Chain link, Stainless  
steel



EMS

Stainless steel knurled  
thumb nut, Knurled



GMC

Flat profile - Round  
guide, Flat profile -  
round guide




PAT123

Pressed stainless  
steel articulating foot  
Ø123, Ø 123




MAC

 Carabiner DIN5299  
steel, Steel



M1

 Worm and wheel set,  
Machined plastic



KSM

Cylindrical steel nut,  
Steel - 1 thread



CHA\_GC\_14SS

Stainless steel garnet  
hinge, To screw

## Complementary products



SRG

Adjustable latch  
clamp with strike  
plate, Stroke from  
117,4mm to 128mm



SRG

Adjustable latch  
clamp with strike  
plate, Stroke from  
78mm to 90mm