


- For fastening two associated parts
- Stress spread uniformly across width
- Absorbs shocks and vibrations
- For information on shear strength, please see technical information
- Material: stainless steel 304

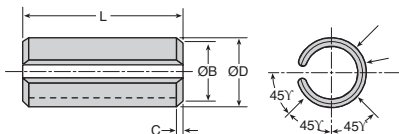

Info.

- Sold by the packet



DISCOUNTS

N° packets	1+	5+	10+	21+
Discount	List	-10%	-20%	On request

Part number	ØD expanded			L	ØB	Chamfer C	Hole Ø		Qty. per packet	Price per packet
	Nom. Ø	Min. Ø	Max. Ø				Min.	Max.		
SRP1.5-6/B	1,5	1,70	1,80	6	1,40	0,50	1,50	1,60	100	9,36 €
SRP1.5-8/B	1,5	1,70	1,80	8	1,40	0,50	1,50	1,60	100	9,99 €
SRP1.5-10/B	1,5	1,70	1,80	10	1,40	0,50	1,50	1,60	100	10,18 €
SRP1.5-14/B	1,5	1,70	1,80	14	1,40	0,50	1,50	1,60	100	10,85 €
SRP1.5-20/B	1,5	1,70	1,80	20	1,40	0,50	1,50	1,60	100	12,93 €
SRP2-5/B	2,0	2,30	2,40	5	1,90	0,70	2,00	2,10	100	10,47 €
SRP2-8/B	2,0	2,30	2,40	8	1,90	0,70	2,00	2,10	100	9,36 €
SRP2-10/B	2,0	2,30	2,40	10	1,90	0,70	2,00	2,10	100	10,85 €
SRP2-12/B	2,0	2,30	2,40	12	1,90	0,70	2,00	2,10	100	10,18 €
SRP2-14/B	2,0	2,30	2,40	14	1,90	0,70	2,00	2,10	100	11,57 €
SRP2-16/B	2,0	2,30	2,40	16	1,90	0,70	2,00	2,10	100	12,25 €
SRP2-18/B	2,0	2,30	2,40	18	1,90	0,70	2,00	2,10	100	12,59 €
SRP2-20/B	2,0	2,30	2,40	20	1,90	0,70	2,00	2,10	100	12,93 €
SRP2-24/B	2,0	2,30	2,40	24	1,90	0,70	2,00	2,10	100	15,02 €
SRP2-30/B	2,0	2,30	2,40	30	1,90	0,70	2,00	2,10	100	17,78 €

*Depending on availability - Dimensions in mm


DISCOUNTS

N° packets	1+	5+	10+	21+
Discount	List	-10%	-20%	On request

Part number	ØD expanded				L	ØB	Chamfer C	Hole Ø		Qty. per packet	Stock*	Price per packet
	Nom. Ø	Min. Ø	Max. Ø	Min.				Max.				
SRP2.5-8/B	2,5	2,80	2,90	8	2,40	0,70	2,50	2,60	100	-	11,50 €	
SRP2.5-10/B	2,5	2,80	2,90	10	2,40	0,70	2,50	2,60	100	✓	11,93 €	
SRP2.5-16/B	2,5	2,80	2,90	16	2,40	0,70	2,50	2,60	100	✓	12,93 €	
SRP2.5-20/B	2,5	2,80	2,78	20	2,40	0,70	2,49	2,60	100	-	13,88 €	
SRP2.5-30/B	2,5	2,80	2,78	30	2,40	0,70	2,49	2,60	100	✓	15,82 €	
SRP3-8/B	3,0	3,30	3,30	8	2,90	0,90	3,00	3,10	100	✓	10,85 €	
SRP3-10/B	3,0	3,30	3,30	10	2,90	0,90	3,00	3,10	100	✓	12,25 €	
SRP3-12/B	3,0	3,30	3,30	12	2,90	0,90	3,00	3,10	100	✓	11,57 €	
SRP3-14/B	3,0	3,30	3,30	14	2,90	0,90	3,00	3,10	100	✓	13,50 €	
SRP3-16/B	3,0	3,30	3,30	16	2,90	0,90	3,00	3,10	100	✓	12,46 €	
SRP3-18/B	3,0	3,30	3,30	18	2,90	0,90	3,00	3,10	100	✓	14,36 €	
SRP3-20/B	3,0	3,30	3,30	20	2,90	0,90	3,00	3,10	100	✓	14,87 €	
SRP3-24/B	3,0	3,30	3,30	24	2,90	0,90	3,00	3,10	100	✓	17,10 €	
SRP3-30/B	3,0	3,30	3,30	30	2,90	0,90	3,00	3,10	100	✓	17,10 €	
SRP3-40/B	3,0	3,30	3,30	40	2,90	0,90	3,00	3,10	100	✓	21,22 €	
SRP4-10/B	4,0	4,40	4,60	10	3,90	1,10	4,00	4,12	100	✓	16,27 €	
SRP4-12/B	4,0	4,40	4,60	12	3,90	1,10	4,00	4,12	100	✓	17,10 €	
SRP4-16/B	4,0	4,40	4,60	16	3,90	1,10	4,00	4,12	100	✓	17,10 €	
SRP4-20/B	4,0	4,40	4,60	20	3,90	1,10	4,00	4,12	100	✓	18,45 €	
SRP4-24/B	4,0	4,40	4,60	24	3,90	1,10	4,00	4,12	100	✓	19,86 €	
SRP4-26/B	4,0	4,40	4,60	26	3,90	1,10	4,00	4,12	100	-	21,22 €	
SRP4-28/B	4,0	4,40	4,60	28	3,90	1,10	4,00	4,12	100	✓	23,97 €	
SRP4-30/B	4,0	4,40	4,60	30	3,90	1,10	4,00	4,12	100	✓	24,66 €	
SRP4-35/B	4,0	4,40	4,60	35	3,90	1,10	4,00	4,12	50	-	14,56 €	
SRP4-40/B	4,0	4,40	4,60	40	3,90	1,10	4,00	4,12	50	✓	15,60 €	
SRP4-45/B	4,0	4,40	4,60	45	3,90	1,10	4,00	4,12	50	✓	16,66 €	
SRP4-50/B	4,0	4,40	4,60	50	3,90	1,10	4,00	4,12	50	✓	18,05 €	
SRP5-10/B	5,0	5,40	5,60	10	4,85	1,30	5,00	5,12	50	-	10,06 €	
SRP5-16/B	5,0	5,40	5,60	16	4,85	1,30	5,00	5,12	50	✓	11,15 €	
SRP5-20/B	5,0	5,40	5,60	20	4,85	1,30	5,00	5,12	50	✓	14,23 €	
SRP5-24/B	5,0	5,40	5,60	24	4,85	1,30	5,00	5,12	50	✓	14,46 €	
SRP5-30/B	5,0	5,40	5,60	30	4,85	1,30	5,00	5,12	50	✓	13,20 €	
SRP5-35/B	5,0	5,40	5,45	35	4,85	1,30	5,00	5,12	50	✓	14,48 €	
SRP5-40/B	5,0	5,40	5,45	40	4,85	1,30	5,00	5,12	50	✓	19,35 €	
SRP5-50/B	5,0	5,40	5,45	50	4,85	1,30	5,00	5,12	50	✓	22,19 €	
SRP6-20/B	6,0	6,40	6,70	20	5,85	1,50	6,00	6,12	50	✓	16,59 €	
SRP6-30/B	6,0	6,40	6,70	30	5,85	1,50	6,00	6,12	50	✓	21,12 €	
SRP6-40/B	6,0	6,40	6,70	40	5,85	1,50	6,00	6,12	50	✓	25,97 €	
SRP6-50/B	6,0	6,40	6,70	50	5,85	1,50	6,00	6,12	50	✓	30,47 €	
SRP8-30/B	8,0	8,50	8,80	30	7,80	2,00	8,00	8,15	25	✓	15,16 €	
SRP8-40/B	8,0	8,50	8,80	40	7,80	2,00	8,00	8,15	10	✓	9,03 €	
SRP8-50/B	8,0	8,50	8,80	50	7,80	2,00	8,00	8,15	10	✓	10,43 €	
SRP10-30/B	10,0	10,50	10,80	30	9,75	2,50	10,00	10,15	10	✓	13,36 €	
SRP10-40/B	10,0	10,50	10,80	40	9,75	2,50	10,00	10,15	10	✓	15,12 €	
SRP10-50/B	10,0	10,50	10,80	50	9,75	2,50	10,00	10,15	10	✓	16,95 €	

*Depending on availability - Dimensions in mm

 Our other products



KITbuh
24V DC motorisation
kit, Planetary gears




BPH
Ball transfer unit plain
fit, High



INS150
Self tapping insert
with collar-coarse
thread, With collar-
coarse t...



MDR_SS
Stainless steel Dee
shackle with eye bolt,
Stainless steel

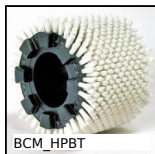

BCM_HPBT
Modular cylindrical
brush, PBT polyester
bristles



QNJ
Single row cylindrical
roller bearing, Single
flange on inner ring



CLB_M
Die cast zinc clamping
lever - female, Zamak



PCLA_M
Technopolymer
clamping lever -
female, Plastic



 
VTLM
3 lobed handle,
Polyamide - Steel



SHA_PTR
Handwheel with
folding handle,



BAB
Hardened stainless
steel ball pin,



FRss
Stainless steel thread
inserts, Stainless steel

Complementary products



DH
Dowel pin, Solid DIN
6325



BOXsap
Boxed set of spring
pins ISO8752, Boxed
set - Split ISO 8752