


- For fastening two associated parts
- Stress spread uniformly across width
- Absorbs shocks and vibrations
- For information on shear strength, please see technical information
- Material: stainless steel 304

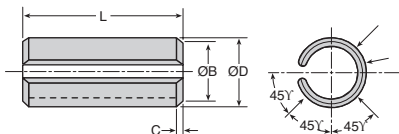

Info.

- Sold by the packet



DISCOUNTS

N° packets	1+	5+	10+	21+
Discount	List	-10%	-20%	On request

Part number	ØD expanded			L	ØB	Chamfer C	Hole Ø		Qty. per packet	Price per packet
	Nom. Ø	Min. Ø	Max. Ø				Min.	Max.		
SRP1.5-6/B	1,5	1,70	1,80	6	1,40	0,50	1,50	1,60	100	9,36 €
SRP1.5-8/B	1,5	1,70	1,80	8	1,40	0,50	1,50	1,60	100	9,99 €
SRP1.5-10/B	1,5	1,70	1,80	10	1,40	0,50	1,50	1,60	100	10,18 €
SRP1.5-14/B	1,5	1,70	1,80	14	1,40	0,50	1,50	1,60	100	10,85 €
SRP1.5-20/B	1,5	1,70	1,80	20	1,40	0,50	1,50	1,60	100	12,93 €
SRP2-5/B	2,0	2,30	2,40	5	1,90	0,70	2,00	2,10	100	10,47 €
SRP2-8/B	2,0	2,30	2,40	8	1,90	0,70	2,00	2,10	100	9,36 €
SRP2-10/B	2,0	2,30	2,40	10	1,90	0,70	2,00	2,10	100	10,85 €
SRP2-12/B	2,0	2,30	2,40	12	1,90	0,70	2,00	2,10	100	10,18 €
SRP2-14/B	2,0	2,30	2,40	14	1,90	0,70	2,00	2,10	100	11,57 €
SRP2-16/B	2,0	2,30	2,40	16	1,90	0,70	2,00	2,10	100	12,25 €
SRP2-18/B	2,0	2,30	2,40	18	1,90	0,70	2,00	2,10	100	12,59 €
SRP2-20/B	2,0	2,30	2,40	20	1,90	0,70	2,00	2,10	100	12,93 €
SRP2-24/B	2,0	2,30	2,40	24	1,90	0,70	2,00	2,10	100	15,02 €
SRP2-30/B	2,0	2,30	2,40	30	1,90	0,70	2,00	2,10	100	17,78 €

*Depending on availability - Dimensions in mm

DISCOUNTS

N° packets	1+	5+	10+	21+
Discount	List	-10%	-20%	On request

Part number	ØD expanded				L	ØB	Chamfer C	Hole Ø		Qty. per packet	Stock*	Price per packet
	Nom. Ø	Min. Ø	Max. Ø	Min.				Max.				
SRP2.5-8/B	2,5	2,80	2,90	8	2,40	0,70	2,50	2,60	100	-	11,50 €	
SRP2.5-10/B	2,5	2,80	2,90	10	2,40	0,70	2,50	2,60	100	✓	11,93 €	
SRP2.5-16/B	2,5	2,80	2,90	16	2,40	0,70	2,50	2,60	100	✓	12,93 €	
SRP2.5-20/B	2,5	2,80	2,78	20	2,40	0,70	2,49	2,60	100	-	13,88 €	
SRP2.5-30/B	2,5	2,80	2,78	30	2,40	0,70	2,49	2,60	100	✓	15,82 €	
SRP3-8/B	3,0	3,30	3,30	8	2,90	0,90	3,00	3,10	100	✓	10,85 €	
SRP3-10/B	3,0	3,30	3,30	10	2,90	0,90	3,00	3,10	100	✓	12,25 €	
SRP3-12/B	3,0	3,30	3,30	12	2,90	0,90	3,00	3,10	100	✓	11,57 €	
SRP3-14/B	3,0	3,30	3,30	14	2,90	0,90	3,00	3,10	100	✓	13,50 €	
SRP3-16/B	3,0	3,30	3,30	16	2,90	0,90	3,00	3,10	100	✓	12,46 €	
SRP3-18/B	3,0	3,30	3,30	18	2,90	0,90	3,00	3,10	100	✓	14,36 €	
SRP3-20/B	3,0	3,30	3,30	20	2,90	0,90	3,00	3,10	100	✓	14,87 €	
SRP3-24/B	3,0	3,30	3,30	24	2,90	0,90	3,00	3,10	100	✓	17,10 €	
SRP3-30/B	3,0	3,30	3,30	30	2,90	0,90	3,00	3,10	100	✓	17,10 €	
SRP3-40/B	3,0	3,30	3,30	40	2,90	0,90	3,00	3,10	100	✓	21,22 €	
SRP4-10/B	4,0	4,40	4,60	10	3,90	1,10	4,00	4,12	100	✓	16,27 €	
SRP4-12/B	4,0	4,40	4,60	12	3,90	1,10	4,00	4,12	100	✓	17,10 €	
SRP4-16/B	4,0	4,40	4,60	16	3,90	1,10	4,00	4,12	100	✓	17,10 €	
SRP4-20/B	4,0	4,40	4,60	20	3,90	1,10	4,00	4,12	100	✓	18,45 €	
SRP4-24/B	4,0	4,40	4,60	24	3,90	1,10	4,00	4,12	100	✓	19,86 €	
SRP4-26/B	4,0	4,40	4,60	26	3,90	1,10	4,00	4,12	100	-	21,22 €	
SRP4-28/B	4,0	4,40	4,60	28	3,90	1,10	4,00	4,12	100	✓	23,97 €	
SRP4-30/B	4,0	4,40	4,60	30	3,90	1,10	4,00	4,12	100	✓	24,66 €	
SRP4-35/B	4,0	4,40	4,60	35	3,90	1,10	4,00	4,12	50	-	14,56 €	
SRP4-40/B	4,0	4,40	4,60	40	3,90	1,10	4,00	4,12	50	✓	15,60 €	
SRP4-45/B	4,0	4,40	4,60	45	3,90	1,10	4,00	4,12	50	✓	16,66 €	
SRP4-50/B	4,0	4,40	4,60	50	3,90	1,10	4,00	4,12	50	✓	18,05 €	
SRP5-10/B	5,0	5,40	5,60	10	4,85	1,30	5,00	5,12	50	-	10,06 €	
SRP5-16/B	5,0	5,40	5,60	16	4,85	1,30	5,00	5,12	50	✓	11,15 €	
SRP5-20/B	5,0	5,40	5,60	20	4,85	1,30	5,00	5,12	50	✓	14,23 €	
SRP5-24/B	5,0	5,40	5,60	24	4,85	1,30	5,00	5,12	50	✓	14,46 €	
SRP5-30/B	5,0	5,40	5,60	30	4,85	1,30	5,00	5,12	50	✓	13,20 €	
SRP5-35/B	5,0	5,40	5,45	35	4,85	1,30	5,00	5,12	50	✓	14,48 €	
SRP5-40/B	5,0	5,40	5,45	40	4,85	1,30	5,00	5,12	50	✓	19,35 €	
SRP5-50/B	5,0	5,40	5,45	50	4,85	1,30	5,00	5,12	50	✓	22,19 €	
SRP6-20/B	6,0	6,40	6,70	20	5,85	1,50	6,00	6,12	50	✓	16,59 €	
SRP6-30/B	6,0	6,40	6,70	30	5,85	1,50	6,00	6,12	50	✓	21,12 €	
SRP6-40/B	6,0	6,40	6,70	40	5,85	1,50	6,00	6,12	50	✓	25,97 €	
SRP6-50/B	6,0	6,40	6,70	50	5,85	1,50	6,00	6,12	50	✓	30,47 €	
SRP8-30/B	8,0	8,50	8,80	30	7,80	2,00	8,00	8,15	25	✓	15,16 €	
SRP8-40/B	8,0	8,50	8,80	40	7,80	2,00	8,00	8,15	10	✓	9,03 €	
SRP8-50/B	8,0	8,50	8,80	50	7,80	2,00	8,00	8,15	10	✓	10,43 €	
SRP10-30/B	10,0	10,50	10,80	30	9,75	2,50	10,00	10,15	10	✓	13,36 €	
SRP10-40/B	10,0	10,50	10,80	40	9,75	2,50	10,00	10,15	10	✓	15,12 €	
SRP10-50/B	10,0	10,50	10,80	50	9,75	2,50	10,00	10,15	10	✓	16,95 €	

*Depending on availability - Dimensions in mm

Our other products



FF20

Offset spur gear reducer, from 5.80 to 23 Nm



DOMI80

Accessories, Clamping lever



YG2

HEAVY DUTY spur gear, Steel 35NCD6



G-ECO

Eco range Spur gear, Steel C45



GP

Spring loaded toggle latch, Standard



PPG

Indexing plunger with flange, With horizontal mounting flange



BTC

End cap for square tube, Standard



 
PRF_BV

Screw block, Panel addition and fastening



DB_ECO

Eco. range steel bevel gear, 2:1



H1

Crossed helical gear crossed axis at 90°, Machined plastic



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane



T10courroie

T type timing belt, T10 Steel cored polyurethane

Complementary products



DH

Dowel pin, Solid DIN 6325



BOXsap

Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752