


- For fastening two associated parts
- Stress spread uniformly across width
- Absorbs shocks and vibrations
- For information on shear strength, please see technical information
- Material: stainless steel 304

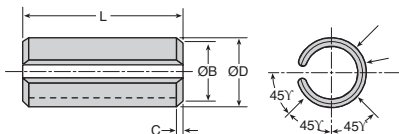

### Info.

- Sold by the packet



### DISCOUNTS

N° packets	1+	5+	10+	21+
Discount	List	-10%	-20%	On request

Part number	ØD expanded			L	ØB	Chamfer C	Hole Ø		Qty. per packet	Price per packet
	Nom. Ø	Min. Ø	Max. Ø				Min.	Max.		
SRP1.5-6/B	1,5	1,70	1,80	6	1,40	0,50	1,50	1,60	100	9,36 €
SRP1.5-8/B	1,5	1,70	1,80	8	1,40	0,50	1,50	1,60	100	9,99 €
SRP1.5-10/B	1,5	1,70	1,80	10	1,40	0,50	1,50	1,60	100	10,18 €
SRP1.5-14/B	1,5	1,70	1,80	14	1,40	0,50	1,50	1,60	100	10,85 €
SRP1.5-20/B	1,5	1,70	1,80	20	1,40	0,50	1,50	1,60	100	12,93 €
SRP2-5/B	2,0	2,30	2,40	5	1,90	0,70	2,00	2,10	100	10,47 €
SRP2-8/B	2,0	2,30	2,40	8	1,90	0,70	2,00	2,10	100	9,36 €
SRP2-10/B	2,0	2,30	2,40	10	1,90	0,70	2,00	2,10	100	10,85 €
SRP2-12/B	2,0	2,30	2,40	12	1,90	0,70	2,00	2,10	100	10,18 €
SRP2-14/B	2,0	2,30	2,40	14	1,90	0,70	2,00	2,10	100	11,57 €
SRP2-16/B	2,0	2,30	2,40	16	1,90	0,70	2,00	2,10	100	12,25 €
SRP2-18/B	2,0	2,30	2,40	18	1,90	0,70	2,00	2,10	100	12,59 €
SRP2-20/B	2,0	2,30	2,40	20	1,90	0,70	2,00	2,10	100	12,93 €
SRP2-24/B	2,0	2,30	2,40	24	1,90	0,70	2,00	2,10	100	15,02 €
SRP2-30/B	2,0	2,30	2,40	30	1,90	0,70	2,00	2,10	100	17,78 €

\*Depending on availability - Dimensions in mm


## DISCOUNTS

<b>N° packets</b>	1+	5+	10+	21+
<b>Discount</b>	List	-10%	-20%	On request

Part number	ØD expanded				L	ØB	Chamfer C	Hole Ø		Qty. per packet	Stock*	Price per packet
	Nom. Ø	Min. Ø	Max. Ø	Min.				Max.				
SRP2.5-8/B	2,5	2,80	2,90	8	2,40	0,70	2,50	2,60	100	-	11,50 €	
SRP2.5-10/B	2,5	2,80	2,90	10	2,40	0,70	2,50	2,60	100	✓	11,93 €	
SRP2.5-16/B	2,5	2,80	2,90	16	2,40	0,70	2,50	2,60	100	✓	12,93 €	
SRP2.5-20/B	2,5	2,80	2,78	20	2,40	0,70	2,49	2,60	100	-	13,88 €	
SRP2.5-30/B	2,5	2,80	2,78	30	2,40	0,70	2,49	2,60	100	✓	15,82 €	
SRP3-8/B	3,0	3,30	3,30	8	2,90	0,90	3,00	3,10	100	✓	10,85 €	
SRP3-10/B	3,0	3,30	3,30	10	2,90	0,90	3,00	3,10	100	✓	12,25 €	
SRP3-12/B	3,0	3,30	3,30	12	2,90	0,90	3,00	3,10	100	✓	11,57 €	
SRP3-14/B	3,0	3,30	3,30	14	2,90	0,90	3,00	3,10	100	✓	13,50 €	
SRP3-16/B	3,0	3,30	3,30	16	2,90	0,90	3,00	3,10	100	✓	12,46 €	
SRP3-18/B	3,0	3,30	3,30	18	2,90	0,90	3,00	3,10	100	✓	14,36 €	
SRP3-20/B	3,0	3,30	3,30	20	2,90	0,90	3,00	3,10	100	✓	14,87 €	
SRP3-24/B	3,0	3,30	3,30	24	2,90	0,90	3,00	3,10	100	✓	17,10 €	
SRP3-30/B	3,0	3,30	3,30	30	2,90	0,90	3,00	3,10	100	✓	17,10 €	
SRP3-40/B	3,0	3,30	3,30	40	2,90	0,90	3,00	3,10	100	✓	21,22 €	
SRP4-10/B	4,0	4,40	4,60	10	3,90	1,10	4,00	4,12	100	✓	16,27 €	
SRP4-12/B	4,0	4,40	4,60	12	3,90	1,10	4,00	4,12	100	✓	17,10 €	
SRP4-16/B	4,0	4,40	4,60	16	3,90	1,10	4,00	4,12	100	✓	17,10 €	
SRP4-20/B	4,0	4,40	4,60	20	3,90	1,10	4,00	4,12	100	✓	18,45 €	
SRP4-24/B	4,0	4,40	4,60	24	3,90	1,10	4,00	4,12	100	✓	19,86 €	
SRP4-26/B	4,0	4,40	4,60	26	3,90	1,10	4,00	4,12	100	-	21,22 €	
SRP4-28/B	4,0	4,40	4,60	28	3,90	1,10	4,00	4,12	100	✓	23,97 €	
SRP4-30/B	4,0	4,40	4,60	30	3,90	1,10	4,00	4,12	100	✓	24,66 €	
SRP4-35/B	4,0	4,40	4,60	35	3,90	1,10	4,00	4,12	50	-	14,56 €	
SRP4-40/B	4,0	4,40	4,60	40	3,90	1,10	4,00	4,12	50	✓	15,60 €	
SRP4-45/B	4,0	4,40	4,60	45	3,90	1,10	4,00	4,12	50	✓	16,66 €	
SRP4-50/B	4,0	4,40	4,60	50	3,90	1,10	4,00	4,12	50	✓	18,05 €	
SRP5-10/B	5,0	5,40	5,60	10	4,85	1,30	5,00	5,12	50	-	10,06 €	
SRP5-16/B	5,0	5,40	5,60	16	4,85	1,30	5,00	5,12	50	✓	11,15 €	
SRP5-20/B	5,0	5,40	5,60	20	4,85	1,30	5,00	5,12	50	✓	14,23 €	
SRP5-24/B	5,0	5,40	5,60	24	4,85	1,30	5,00	5,12	50	✓	14,46 €	
SRP5-30/B	5,0	5,40	5,60	30	4,85	1,30	5,00	5,12	50	✓	13,20 €	
SRP5-35/B	5,0	5,40	5,45	35	4,85	1,30	5,00	5,12	50	✓	14,48 €	
SRP5-40/B	5,0	5,40	5,45	40	4,85	1,30	5,00	5,12	50	✓	19,35 €	
SRP5-50/B	5,0	5,40	5,45	50	4,85	1,30	5,00	5,12	50	✓	22,19 €	
SRP6-20/B	6,0	6,40	6,70	20	5,85	1,50	6,00	6,12	50	✓	16,59 €	
SRP6-30/B	6,0	6,40	6,70	30	5,85	1,50	6,00	6,12	50	✓	21,12 €	
SRP6-40/B	6,0	6,40	6,70	40	5,85	1,50	6,00	6,12	50	✓	25,97 €	
SRP6-50/B	6,0	6,40	6,70	50	5,85	1,50	6,00	6,12	50	✓	30,47 €	
SRP8-30/B	8,0	8,50	8,80	30	7,80	2,00	8,00	8,15	25	✓	15,16 €	
SRP8-40/B	8,0	8,50	8,80	40	7,80	2,00	8,00	8,15	10	✓	9,03 €	
SRP8-50/B	8,0	8,50	8,80	50	7,80	2,00	8,00	8,15	10	✓	10,43 €	
SRP10-30/B	10,0	10,50	10,80	30	9,75	2,50	10,00	10,15	10	✓	13,36 €	
SRP10-40/B	10,0	10,50	10,80	40	9,75	2,50	10,00	10,15	10	✓	15,12 €	
SRP10-50/B	10,0	10,50	10,80	50	9,75	2,50	10,00	10,15	10	✓	16,95 €	

\*Depending on availability - Dimensions in mm

## Our other products

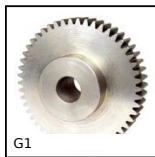

G1

Steel spur gear, Steel  
20NCD2



SVT20

Screwjack with  
travelling screw, with  
translating screw



VDSQC8

Sliding lock  
adjustment system,  
Blocking wedge



PRF\_RR

Coupling bar for  
aluminium profile,  
Coupling bar



J53

Spur gear coaxial  
gearbox, from 0.43 to  
1.15 - In-line



FBL6000\_K19

Brush strip per meter  
horsehair fibres Ø0.2,  
Black horsehair



T10\_30\_AL

T type timing pulley,  
Economy range - T10  
aluminium



BAN

Angular clamp,  
Universal



PM2

Worm and wheel set,  
Non hardened steel



NPCR

Adjustable cell  
support, Adjustable



BLHM70

Right angled gearbox,  
up to 128 Nm



CMA

Eye bolt, Steel

## Complementary products



DH

Dowel pin, Solid DIN  
6325



BOXsap

Boxed set of spring  
pins ISO8752, Boxed  
set - Split ISO 8752