


Ratio

Stainless steel 304L

1:1

- Module 0.8 to 2.5
- Pressure angle 20°
- Teeth Gleason
- Material:
stainless steel 304L
- Two gears must be ordered to make a pair

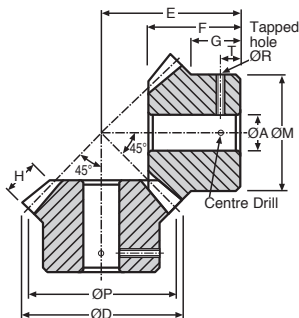

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm					
	2.5 MOD	2.0 MOD	1.5 MOD	1.25 MOD	1.0 MOD	0.8 MOD
Torque (Nm)	4.30	2.20	0.94	0.71	0.57	0.14
Power (kW)	0.455	0.231	0.097	0.08	0.03	0.015

DISCOUNTS

Qty	1+	6+	20+
Disc. List	-12%	On request	On request

Part number	Teeth		ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	Price each 1 to 5
	Z	Module											
SSB0.8-16	16	0.8	12,80	20	13,93	6	10	16,00	12,21	3,00	M3	7,00	44,47 €
SSB0.8-25	25	0.8	20,00	20	21,13	6	16	13,35	8,00	4,24	M3	5,00	48,27 €
SSB0.8-30	30	0.8	24,00	20	25,13	6	20	11,96	6,00	5,09	M3	4,00	52,17 €
SSB1-20	20	1	20,00	25	21,41	8	18	18,45	14,00	4,24	M4	8,00	53,13 €
SSB1-30	30	1	30,00	25	31,41	8	26	14,95	8,00	6,35	M4	5,00	60,39 €
SSB1.25-20	20	1.25	25,00	23	26,70	8	22	15,27	9,00	6,00	M4	3,50	55,81 €
SSB1.25-30	30	1.25	37,50	36	39,30	10	30	23,47	13,50	8,00	M4	5,00	63,23 €
SSB1.5-20	20	1.5	30,00	35	32,12	10	26	25,17	18,00	6,35	M4	10,00	57,62 €
SSB1.5-30	30	1.5	45,00	35	47,12	10	38	19,92	9,00	9,50	M4	5,00	70,91 €
SSB2-20	20	2	40,00	42	43,00	12	34	29,00	19,00	8,50	M5	10,00	67,40 €
SSB2-30	30	2	60,00	42	63,00	12	50	21,87	7,00	12,70	M5	4,00	84,44 €
SSB2.5-16	16	2.5	40,00	50	43,50	15	35	36,80	27,50	8,00	M5	15,00	68,91 €
SSB2.5-25	25	2.5	62,50	50	66,00	15	55	30,50	15,00	15,00	M5	8,00	97,78 €


Dimensions in mm

Our other products



SLV

Vertical toggle clamp,
Vertical Lever Clamp -
stainless steel

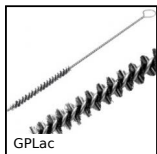

GPLac

Brush, steel



BAC105

Storage bin, 8mm




AK

Bellows coupling
Gerwah®, from 36 to
800Nm



EKN

Bellows coupling
Gerwah®, from 0.5 to
12Nm

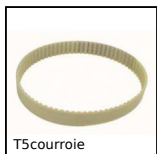


T5courroie

T type timing belt, T5
Steel cored
polyurethane



ACL-APB

Closing system for
aluminium profile,
Magnetic door stop

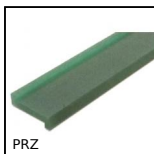

PRZ

Wear strip for slat top
chain, Z profile to be
clipped



RJA00_02

Sealing strip, Clipping



HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



PTA150

Articulated levelling
foot, pressed base
Ø150, Ø 150



CMM


Male rod ends DIN
ISO12240-4, Steel /
bronze

Complementary products



MEB

Moulded plastic bevel
gear (nylon), 1:1

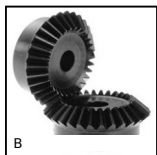

B

Steel bevel gear, 1:1