


Ratio

Stainless steel 304L

1:1

- Module 0.8 to 2.5
- Pressure angle 20°
- Teeth Gleason
- Material:
stainless steel 304L
- Two gears must be ordered to make a pair

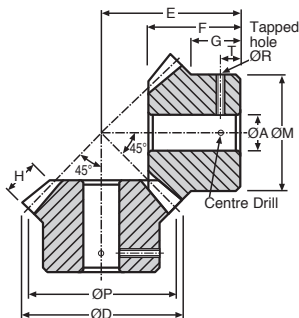

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm					
	2.5 MOD	2.0 MOD	1.5 MOD	1.25 MOD	1.0 MOD	0.8 MOD
Torque (Nm)	4.30	2.20	0.94	0.71	0.57	0.14
Power (kW)	0.455	0.231	0.097	0.08	0.03	0.015

DISCOUNTS

Qty	1+	6+	20+
Disc. List	-12%	On request	On request

Part number	Teeth		ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	Price each 1 to 5
	Z	Module											
SSB0.8-16	16	0.8	12,80	20	13,93	6	10	16,00	12,21	3,00	M3	7,00	44,47 €
SSB0.8-25	25	0.8	20,00	20	21,13	6	16	13,35	8,00	4,24	M3	5,00	48,27 €
SSB0.8-30	30	0.8	24,00	20	25,13	6	20	11,96	6,00	5,09	M3	4,00	52,17 €
SSB1-20	20	1	20,00	25	21,41	8	18	18,45	14,00	4,24	M4	8,00	53,13 €
SSB1-30	30	1	30,00	25	31,41	8	26	14,95	8,00	6,35	M4	5,00	60,39 €
SSB1.25-20	20	1.25	25,00	23	26,70	8	22	15,27	9,00	6,00	M4	3,50	55,81 €
SSB1.25-30	30	1.25	37,50	36	39,30	10	30	23,47	13,50	8,00	M4	5,00	63,23 €
SSB1.5-20	20	1.5	30,00	35	32,12	10	26	25,17	18,00	6,35	M4	10,00	57,62 €
SSB1.5-30	30	1.5	45,00	35	47,12	10	38	19,92	9,00	9,50	M4	5,00	70,91 €
SSB2-20	20	2	40,00	42	43,00	12	34	29,00	19,00	8,50	M5	10,00	67,40 €
SSB2-30	30	2	60,00	42	63,00	12	50	21,87	7,00	12,70	M5	4,00	84,44 €
SSB2.5-16	16	2.5	40,00	50	43,50	15	35	36,80	27,50	8,00	M5	15,00	68,91 €
SSB2.5-25	25	2.5	62,50	50	66,00	15	55	30,50	15,00	15,00	M5	8,00	97,78 €

Dimensions in mm

Our other products



ZBconique

Machined plastic
bevel gear , 1:1



TRM

Spur round rack, Steel
- module 1-6



PLM-16A

Magnetic stud with
threaded hole, With
threaded hole



PSG25

Spur gear - precision
range, Case hardened
steel 20NCD2



RPCplss

Swivel castor with
plate, Stainless steel -
Polyamide



WING

Manually tightened
wing nut, Steel (ANSI
B18-17)



PGB

Accessory-holder for
aluminium profile,
Tool holder



PDD

Actuating plunger,
Non-rotating detector
shaft



 
HTD8M_20

HTD Heavy duty
timing pulley, HTD8
Cast



H4

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



T5courroie

T type timing belt, T5
Steel cored
polyurethane



MRS

 
Stainless steel metric
section rack, Stainless
steel

Complementary products



ZBconique

Machined plastic
bevel gear, 1:1



B

Steel bevel gear, 1:1