


Ratio

Stainless steel 304L

1:1

- Module 0.8 to 2.5
- Pressure angle 20°
- Teeth Gleason
- Material:
stainless steel 304L
- Two gears must be ordered to make a pair

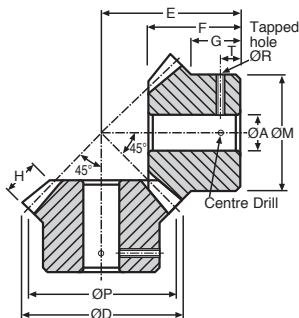

| TORQUE AND POWER INDICATION | For 20 teeth at 1000 rpm | | | | | |
|-----------------------------|--------------------------|---------|---------|----------|---------|---------|
| | 2.5 MOD | 2.0 MOD | 1.5 MOD | 1.25 MOD | 1.0 MOD | 0.8 MOD |
| Torque (Nm) | 4.30 | 2.20 | 0.94 | 0.71 | 0.57 | 0.14 |
| Power (kW) | 0.455 | 0.231 | 0.097 | 0.08 | 0.03 | 0.015 |


DISCOUNTS

| Qty | 1+ | 6+ | 20+ |
|------------|------|------------|------------|
| Disc. List | -12% | On request | On request |

| Part number | Teeth | | ØP | E | ØD | ØA | ØM | F | G | H | ØR | T | Price each 1 to 5 |
|-------------|-------|--------|-------|----|-------|----|----|-------|-------|-------|----|-------|-------------------|
| | Z | Module | | | | | | | | | | | |
| SSB0.8-16 | 16 | 0.8 | 12,80 | 20 | 13,93 | 6 | 10 | 16,00 | 12,21 | 3,00 | M3 | 7,00 | 44,47 € |
| SSB0.8-25 | 25 | 0.8 | 20,00 | 20 | 21,13 | 6 | 16 | 13,35 | 8,00 | 4,24 | M3 | 5,00 | 48,27 € |
| SSB0.8-30 | 30 | 0.8 | 24,00 | 20 | 25,13 | 6 | 20 | 11,96 | 6,00 | 5,09 | M3 | 4,00 | 52,17 € |
| SSB1-20 | 20 | 1 | 20,00 | 25 | 21,41 | 8 | 18 | 18,45 | 14,00 | 4,24 | M4 | 8,00 | 53,13 € |
| SSB1-30 | 30 | 1 | 30,00 | 25 | 31,41 | 8 | 26 | 14,95 | 8,00 | 6,35 | M4 | 5,00 | 60,39 € |
| SSB1.25-20 | 20 | 1.25 | 25,00 | 23 | 26,70 | 8 | 22 | 15,27 | 9,00 | 6,00 | M4 | 3,50 | 55,81 € |
| SSB1.25-30 | 30 | 1.25 | 37,50 | 36 | 39,30 | 10 | 30 | 23,47 | 13,50 | 8,00 | M4 | 5,00 | 63,23 € |
| SSB1.5-20 | 20 | 1.5 | 30,00 | 35 | 32,12 | 10 | 26 | 25,17 | 18,00 | 6,35 | M4 | 10,00 | 57,62 € |
| SSB1.5-30 | 30 | 1.5 | 45,00 | 35 | 47,12 | 10 | 38 | 19,92 | 9,00 | 9,50 | M4 | 5,00 | 70,91 € |
| SSB2-20 | 20 | 2 | 40,00 | 42 | 43,00 | 12 | 34 | 29,00 | 19,00 | 8,50 | M5 | 10,00 | 67,40 € |
| SSB2-30 | 30 | 2 | 60,00 | 42 | 63,00 | 12 | 50 | 21,87 | 7,00 | 12,70 | M5 | 4,00 | 84,44 € |
| SSB2.5-16 | 16 | 2.5 | 40,00 | 50 | 43,50 | 15 | 35 | 36,80 | 27,50 | 8,00 | M5 | 15,00 | 68,91 € |
| SSB2.5-25 | 25 | 2.5 | 62,50 | 50 | 66,00 | 15 | 55 | 30,50 | 15,00 | 15,00 | M5 | 8,00 | 97,78 € |

Dimensions in mm

Our other products

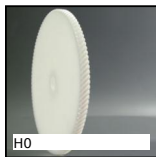

H0

Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



CHCCS

Socket headed screw,
Stainless steel - A2



CHAsb28

Roll of hinge without
pin, Plastic hinge



PTA40ssEB

Articulated foot whit
sheet metal base
Ø40, 3000N



HTD8M-BAR

HTD type tooth bar
stock, HTD8



BPMc

Stainless steel slotted
spring plunger with
ceramic ball tip, 303
St...



RAGFLOWsupport

Floway2® Roller track
accessory, Roller
track support



HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



PDM_PDV

Detectable plastic
palm grip, by metal



DFG

Flat suction cup,
nitrile



GAL48_OMNI

Omni-directional
roller, Omni-



LACT_SS

 
Adjustable Stainless
steel cam lever, Male

Complementary products



ZBconique

Machined plastic
bevel gear, 1:1



B

Steel bevel gear, 1:1