


Ratio

Stainless steel 304L

1:1

- Module 0.8 to 2.5
- Pressure angle 20°
- Teeth Gleason
- Material:
stainless steel 304L
- Two gears must be ordered to make a pair

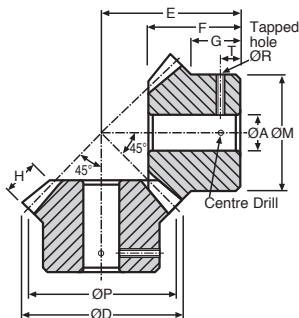

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm					
	2.5 MOD	2.0 MOD	1.5 MOD	1.25 MOD	1.0 MOD	0.8 MOD
Torque (Nm)	4.30	2.20	0.94	0.71	0.57	0.14
Power (kW)	0.455	0.231	0.097	0.08	0.03	0.015

DISCOUNTS

Qty	1+	6+	20+
Disc. List	-12%	On request	On request

Part number	Teeth		ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	Price each 1 to 5
	Z	Module											
SSB0.8-16	16	0.8	12,80	20	13,93	6	10	16,00	12,21	3,00	M3	7,00	44,47 €
SSB0.8-25	25	0.8	20,00	20	21,13	6	16	13,35	8,00	4,24	M3	5,00	48,27 €
SSB0.8-30	30	0.8	24,00	20	25,13	6	20	11,96	6,00	5,09	M3	4,00	52,17 €
SSB1-20	20	1	20,00	25	21,41	8	18	18,45	14,00	4,24	M4	8,00	53,13 €
SSB1-30	30	1	30,00	25	31,41	8	26	14,95	8,00	6,35	M4	5,00	60,39 €
SSB1.25-20	20	1.25	25,00	23	26,70	8	22	15,27	9,00	6,00	M4	3,50	55,81 €
SSB1.25-30	30	1.25	37,50	36	39,30	10	30	23,47	13,50	8,00	M4	5,00	63,23 €
SSB1.5-20	20	1.5	30,00	35	32,12	10	26	25,17	18,00	6,35	M4	10,00	57,62 €
SSB1.5-30	30	1.5	45,00	35	47,12	10	38	19,92	9,00	9,50	M4	5,00	70,91 €
SSB2-20	20	2	40,00	42	43,00	12	34	29,00	19,00	8,50	M5	10,00	67,40 €
SSB2-30	30	2	60,00	42	63,00	12	50	21,87	7,00	12,70	M5	4,00	84,44 €
SSB2.5-16	16	2.5	40,00	50	43,50	15	35	36,80	27,50	8,00	M5	15,00	68,91 €
SSB2.5-25	25	2.5	62,50	50	66,00	15	55	30,50	15,00	15,00	M5	8,00	97,78 €

Dimensions in mm

Our other products



CLB_M

Die cast zinc clamping lever - female, Zamak



RBGpl

Fixed castor with plate, Steel - grey rubber



 
HTD5M_09

HTD Heavy duty timing pulley, HTD5 Aluminium



PPJ

Indexing plunger with flange, With horizontal mounting flange and pu...




RPP

Connecting plate for RPP type timing belts, RPP14



CHAK

 Hi-Klik TM indent hinge, Hi-Klik™ - Detent hinge



PRF-GUM

Aluminium profile anodising polisher, Polishing block



PPV2R

Adjustable suction-cup support, Increased grip



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot



SH1

Parallel axis helical gear, Machined plastic (delrin)



ACL-PL

 
Joining plate for aluminium profile, Joint plate - 176x86 mm

Complementary products



ZBconique

Machined plastic bevel gear, 1:1



B

Steel bevel gear, 1:1