


Ratio

Stainless steel 304L

1:1

- **Module 0.8 to 2.5**
- Pressure angle 20°
- Teeth Gleason
- Material:
stainless steel 304L
- Two gears must be ordered to make a pair

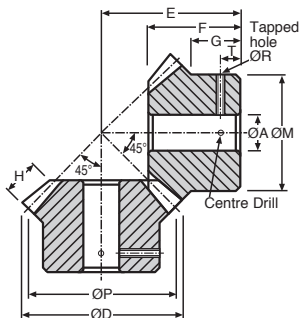

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm					
	2.5 MOD	2.0 MOD	1.5 MOD	1.25 MOD	1.0 MOD	0.8 MOD
Torque (Nm)	4.30	2.20	0.94	0.71	0.57	0.14
Power (kW)	0.455	0.231	0.097	0.08	0.03	0.015

DISCOUNTS

Qty	1+	6+	20+
Disc. List	-12%	On request	On request

Part number	Teeth		ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	Price each 1 to 5
	Z	Module											
SSB0.8-16	16	0.8	12,80	20	13,93	6	10	16,00	12,21	3,00	M3	7,00	44,47 €
SSB0.8-25	25	0.8	20,00	20	21,13	6	16	13,35	8,00	4,24	M3	5,00	48,27 €
SSB0.8-30	30	0.8	24,00	20	25,13	6	20	11,96	6,00	5,09	M3	4,00	52,17 €
SSB1-20	20	1	20,00	25	21,41	8	18	18,45	14,00	4,24	M4	8,00	53,13 €
SSB1-30	30	1	30,00	25	31,41	8	26	14,95	8,00	6,35	M4	5,00	60,39 €
SSB1.25-20	20	1,25	25,00	23	26,70	8	22	15,27	9,00	6,00	M4	3,50	55,81 €
SSB1.25-30	30	1,25	37,50	36	39,30	10	30	23,47	13,50	8,00	M4	5,00	63,23 €
SSB1.5-20	20	1,5	30,00	35	32,12	10	26	25,17	18,00	6,35	M4	10,00	57,62 €
SSB1.5-30	30	1,5	45,00	35	47,12	10	38	19,92	9,00	9,50	M4	5,00	70,91 €
SSB2-20	20	2	40,00	42	43,00	12	34	29,00	19,00	8,50	M5	10,00	67,40 €
SSB2-30	30	2	60,00	42	63,00	12	50	21,87	7,00	12,70	M5	4,00	84,44 €
SSB2.5-16	16	2,5	40,00	50	43,50	15	35	36,80	27,50	8,00	M5	15,00	68,91 €
SSB2.5-25	25	2,5	62,50	50	66,00	15	55	30,50	15,00	15,00	M5	8,00	97,78 €

Dimensions in mm

Our other products



H1

90° crossed axis
helical gear, Machined
plastic (delrin)



CHA60

Hinge, Rectangular,
drilled or countersunk



RURT

Wheel pivoting with
central hole,
Polyurethane -
Aluminium rim (Free



ACL-APB

Closing system,
Magnetic door stop



UCF_SS

Flange bearing,
Stainless steel



HLA19

Right angle bevel
gearbox, Up to 43Nm



ETP-EX

Hydraulic locking
assembly, ETP-
EXPRESS® - Steel



PFL

P-FLEX, Set screw



PRES3HR

Manual bench press,
Force up to 400kg



PRF4545

Standard stainless
steel profile, 45 x 45
mm



HLC19

Right angle bevel
gearbox, Up to 43Nm



DB

 
Bevel gear - Steel
60C40, 2:1

Complementary products



MEB

Moulded plastic bevel
gear (nylon), 1:1



B

Bevel gear - Steel
60C40, 1:1



B_ECO

Bevel gear - Steel
C43, 1:1