

- Compensates for alignment and parallelism between shaft and housing
- Allows oscillating movements at slow speeds
- Material: Self-lubricating stainless steel Uniflon®E
- Requires a P7 toleranced housing

Advantages


- No lubrication or other maintenance required

Uses

- Occasional heavy loads
- Areas where maintenance would be difficult



Swiss precision

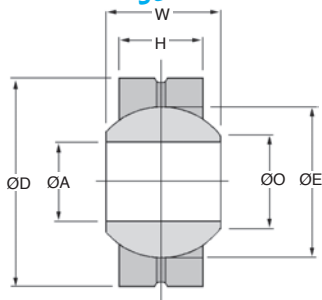

DISCOUNTS

Qty	1+	10+	24+
Disc.	List	-20%	On request

Part number	Static radial load (daN)	Static axial load (daN)	ØA (H6)	ØD (h6)	H	ØØ	W	Sphere ØE	Weight (g)	Price each 1 to 9
SSE3.45	790	250	3	12	4,50	5,18	6	7,93	4	104,27 €
SSE5.45	1500	440	5	16	6,00	7,71	8	11,11	9	96,07 €
SSE6.45	1960	500	6	18	6,75	8,96	9	12,70	12	103,58 €
SSE8.45	3170	620	8	22	9,00	10,40	12	15,88	24	107,35 €
SSE10.45	4530	750	10	26	10,50	12,92	14	19,05	38	137,84 €
SSE12.45	6040	880	12	30	12,00	15,43	16	22,23	57	115,16 €
SSE14.45	7550	1000	14	34	13,50	16,86	19	25,40	83	195,85 €
SSE16.45	9440	1130	16	38	15,00	19,39	21	28,58	110	272,29 €
SSE18.45	11780	1250	18	42	16,50	21,89	23	31,75	150	383,99 €

Dimensions in mm

Our other products



Q3
Double row angular contact ball bearing, Angular contact - Steel



NSA
Adjustable clamp, Articulated



DIL
Lever operated locking bolt, lever clamp



BLM
Spring loaded plunger with ball tip, Stainless steel body



HLA19
Right angle spiro bevel gearbox, Up to 43Nm



DOMI50
Domino 50 adjustable slide, Slide DOMILINE 50



PTAf100-PAMF100
Articulated fixable foot with pressed base $\varnothing 100$, $\varnothing 100$



M0
Worm and wheel set, Machined plastic (delrin)



R206
Die spring ISO10243, Extra-heavy



DPAR_DKON
Conical elasto buffer, Steel



P20
Worm and wheel gear reducer, up to 5 Nm



BMF
Knurled knob - female, Knurled - blind

Complementary products



CSSSS
Stainless steel spherical bearing, Stainless steel / PTFE