



- Quality standard 9
- Pressure angle 20°

Torque and power indication			
For 50 teeth at 1000 rpm			
	StS 304L	brass	fibre
Nm	2.600	1.250	1
kW	0.254	0.134	0.104

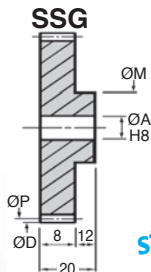

stainless steel

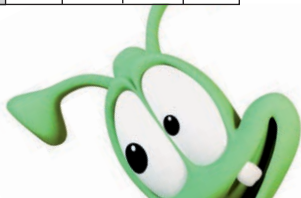

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Teeth Z	pcd ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5
SSG1-12-304L	12	12	14	14	6	25,99 €
SSG1-15-304L	15	15	17	12	8	26,66 €
SSG1-16-304L	16	16	18	12	8	28,08 €
SSG1-18-304L	18	18	20	15	8	28,96 €
SSG1-20-304L	20	20	22	15	8	29,04 €
SSG1-22-304L	22	22	24	15	8	30,18 €
SSG1-24-304L	24	24	26	15	8	30,30 €
SSG1-25-304L	25	25	27	15	8	30,97 €
SSG1-26-304L	26	26	28	15	8	32,30 €
SSG1-28-304L	28	28	30	15	8	33,58 €
SSG1-30-304L	30	30	32	20	8	31,41 €
SSG1-32-304L	32	32	34	20	8	37,17 €
SSG1-36-304L	36	36	38	20	8	41,95 €
SSG1-40-304L	40	40	42	20	8	45,52 €
SSG1-44-304L	44	44	46	20	8	48,88 €
SSG1-48-304L	48	48	50	20	8	52,05 €
SSG1-50-304L	50	50	52	30	10	55,70 €
SSG1-54-304L	54	54	56	30	10	60,61 €
SSG1-56-304L	56	56	58	30	10	61,68 €
SSG1-60-304L	60	60	62	30	10	69,60 €
SSG1-64-304L	64	64	66	30	10	76,93 €
SSG1-66-304L	66	66	68	30	10	88,38 €
SSG1-70-304L	70	70	72	30	10	93,05 €



Gears available up to this size



SSG1-590-304L	590	590	592	Dimensions: contact us		on request
---------------	-----	-----	-----	------------------------	--	------------


Dimensions in mm

Our other products



PITA

Locking bolt, with T handle

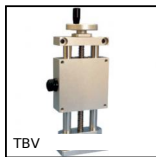

TBV

Manual lifting tables, 20kg



CDC

Conical compression spring, Conical



VRC2

Retaining clamp, dual sided, Dual sided




CHAR6035

Spring hinge, screwed/welded



MEB

 Moulded plastic bevel gear (nylon), 1:1



NK80

Drylin®N miniature guiding system, Width 80mm



CHINV

Invisible hinge, Invisible - 90° opening



BMM

Knurled knob - male, Knurled



PRF-CHAR-POU

Tool holder for aluminium profile, Moveable tool holder



M0

Worm and wheel set, Hardened steel



BAGO

Locking rings in stainless steel, Stainless steel

Complementary products



MRS

Stainless steel metric section rack, Stainless steel



TRMSS

Spur round rack, Stainless steel - module 1-5