



- Quality standard 9
- Pressure angle 20°

Torque and power indication			
For 50 teeth at 1000 rpm			
	StS 304L	brass	fibre
Nm	2.600	1.250	1
kW	0.254	0.134	0.104

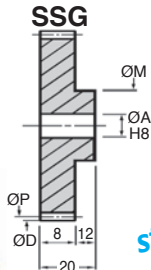

stainless steel

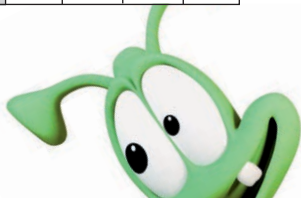

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Teeth Z	pcd ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5
SSG1-12-304L	12	12	14	14	6	25,99 €
SSG1-15-304L	15	15	17	12	8	26,66 €
SSG1-16-304L	16	16	18	12	8	28,08 €
SSG1-18-304L	18	18	20	15	8	28,96 €
SSG1-20-304L	20	20	22	15	8	29,04 €
SSG1-22-304L	22	22	24	15	8	30,18 €
SSG1-24-304L	24	24	26	15	8	30,30 €
SSG1-25-304L	25	25	27	15	8	30,97 €
SSG1-26-304L	26	26	28	15	8	32,30 €
SSG1-28-304L	28	28	30	15	8	33,58 €
SSG1-30-304L	30	30	32	20	8	31,41 €
SSG1-32-304L	32	32	34	20	8	37,17 €
SSG1-36-304L	36	36	38	20	8	41,95 €
SSG1-40-304L	40	40	42	20	8	45,52 €
SSG1-44-304L	44	44	46	20	8	48,88 €
SSG1-48-304L	48	48	50	20	8	52,05 €
SSG1-50-304L	50	50	52	30	10	55,70 €
SSG1-54-304L	54	54	56	30	10	60,61 €
SSG1-56-304L	56	56	58	30	10	61,68 €
SSG1-60-304L	60	60	62	30	10	69,60 €
SSG1-64-304L	64	64	66	30	10	76,93 €
SSG1-66-304L	66	66	68	30	10	88,38 €
SSG1-70-304L	70	70	72	30	10	93,05 €

Gears available up to this size

SSG1-590-304L	590	590	592	Dimensions: contact us	on request
---------------	-----	-----	-----	------------------------	------------


Dimensions in mm

Our other products




H2

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2

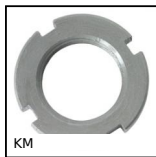

KM

Bearing locknut,
Locknut KM

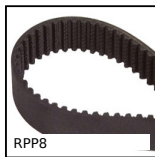

RPP8

RPP heavy duty
timing belt, RPP8



PCP

Cell carrier assembly,
Ready assembled



RFVcap

Stainless steel
protective cover,
Closed protective
cover



LRX

Linear roller slide,
Chariot - from 9410 N
to 101000 N



AZY

Cylindrical elasto
mount, Steel



SSE

Stainless steel
spherical bearing,
Stainless steel / PTFE



NPR

Reflector support,



NIN

Self-locking nut, A2
Stainless steel



P70


Worm and wheel gear
reducer, up to 164



EFSM

Igubal® flange
bearing, Polymer

Complementary products

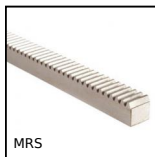

MRS

Stainless steel metric
section rack, Stainless
steel



TRMSS

Spur round rack,
Stainless steel -
module 1-5