

Stainless steel spur gear




Module 2.0

304L stainless steel



- Quality standard 9
- Pressure angle 20°

| Torque and power indication | | | |
|-----------------------------|----------|-------|-------|
| For 50 teeth at 1000 rpm | | | |
| | StS 304L | brass | fibre |
| Nm | 25 | 12,50 | 10 |
| kW | 2,61 | 1,32 | 1,04 |

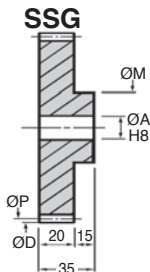

stainless steel

DISCOUNTS

| Qty | 1+ | 6+ | 20+ |
|-------|-----------|------------|------------|
| Disc. | List -12% | On request | On request |


| Part number | Teeth Z | pcd ØP | Outside ØD | Boss ØM | Bore ØA | Price each 1 to 5 |
|--------------|---------|--------|------------|---------|---------|-------------------|
| SSG2-12-304L | 12 | 24 | 28 | 28 | 12 | 42,73 € |
| SSG2-15-304L | 15 | 30 | 34 | 25 | 15 | 37,01 € |
| SSG2-16-304L | 16 | 32 | 36 | 25 | 15 | 39,40 € |
| SSG2-18-304L | 18 | 36 | 40 | 30 | 15 | 44,70 € |
| SSG2-20-304L | 20 | 40 | 44 | 30 | 15 | 47,77 € |
| SSG2-22-304L | 22 | 44 | 48 | 35 | 15 | 53,72 € |
| SSG2-24-304L | 24 | 48 | 52 | 35 | 15 | 59,15 € |
| SSG2-30-304L | 30 | 60 | 64 | 40 | 20 | 77,10 € |
| SSG2-32-304L | 32 | 64 | 68 | 40 | 20 | 79,66 € |
| SSG2-36-304L | 36 | 72 | 76 | 50 | 20 | 92,60 € |
| SSG2-40-304L | 40 | 80 | 84 | 50 | 20 | 148,67 € |
| SSG2-44-304L | 44 | 88 | 92 | 50 | 20 | 204,32 € |
| SSG2-46-304L | 46 | 92 | 96 | 50 | 20 | 204,32 € |
| SSG2-48-304L | 48 | 96 | 100 | 50 | 20 | 204,32 € |
| SSG2-50-304L | 50 | 100 | 104 | 50 | 20 | 234,38 € |
| SSG2-54-304L | 54 | 108 | 112 | 50 | 20 | 234,38 € |
| SSG2-56-304L | 56 | 112 | 116 | 50 | 20 | 267,43 € |
| SSG2-60-304L | 60 | 120 | 124 | 50 | 20 | 267,43 € |
| SSG2-64-304L | 64 | 128 | 132 | 50 | 20 | 304,14 € |
| SSG2-66-304L | 66 | 132 | 136 | 50 | 20 | 322,97 € |
| SSG2-70-304L | 70 | 140 | 144 | 50 | 20 | 336,13 € |

Gears available up to this size

| | | | | | |
|---------------|-----|-----|-----|------------------------|------------|
| SSG2-290-304L | 290 | 580 | 584 | Dimensions: contact us | on request |
|---------------|-----|-----|-----|------------------------|------------|

*Depending on availability - Dimensions in mm

 Our other products



Standard aluminium profile, 45 x 45 mm - R90°



Guidance brush - Rail, Rail



Spur gear - precision range, Case hardened steel 20NCD2



Storage bin, 8mm



Square tube connector, Fixed angle



Moulded plastic bevel gear (nylon), 3:1



Cell carrier assembly, Ready assembled



Adjusting nut, Fine thread



Crossed helical gear crossed axis at 90°, Steel 20NCD2



Universal latch key, Universal latch key

 


Oldham coupling, With set screw



Parallel axis helical gear, Machined plastic (delrin)

Complementary products



Stainless steel metric section rack, Stainless steel



Spur round rack, Stainless steel - module 1-5