

Stainless steel spur gear




Module 2.0

304L stainless steel



- Quality standard 9
- Pressure angle 20°

Torque and power indication			
For 50 teeth at 1000 rpm			
	StS 304L	brass	fibre
Nm	25	12,50	10
kW	2,61	1,32	1,04

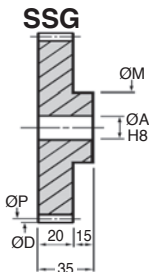

stainless steel

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -12%	On request	On request

Part number	Teeth Z	pcd ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5
SSG2-12-304L	12	24	28	28	12	42,73 €
SSG2-15-304L	15	30	34	25	15	37,01 €
SSG2-16-304L	16	32	36	25	15	39,40 €
SSG2-18-304L	18	36	40	30	15	44,70 €
SSG2-20-304L	20	40	44	30	15	47,77 €
SSG2-22-304L	22	44	48	35	15	53,72 €
SSG2-24-304L	24	48	52	35	15	59,15 €
SSG2-30-304L	30	60	64	40	20	77,10 €
SSG2-32-304L	32	64	68	40	20	79,66 €
SSG2-36-304L	36	72	76	50	20	92,60 €
SSG2-40-304L	40	80	84	50	20	148,67 €
SSG2-44-304L	44	88	92	50	20	204,32 €
SSG2-46-304L	46	92	96	50	20	204,32 €
SSG2-48-304L	48	96	100	50	20	204,32 €
SSG2-50-304L	50	100	104	50	20	234,38 €
SSG2-54-304L	54	108	112	50	20	234,38 €
SSG2-56-304L	56	112	116	50	20	267,43 €
SSG2-60-304L	60	120	124	50	20	267,43 €
SSG2-64-304L	64	128	132	50	20	304,14 €
SSG2-66-304L	66	132	136	50	20	322,97 €
SSG2-70-304L	70	140	144	50	20	336,13 €

Gears available up to this size

SSG2-290-304L	290	580	584	Dimensions: contact us	on request
---------------	-----	-----	-----	------------------------	------------

*Depending on availability - Dimensions in mm

Our other products



VQTplqn

Quarter-turn clamp lock - Clamping plate, Flush mounting



HTD5M_15

HTD Heavy duty timing pulley, HTD5 Steel



CM_CO

Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



M1

Worm and wheel set, Hardened steel



PARF110

Pressed steel base rigid foot, Swivelling Ø110



 
DCA

Suction cup, 1.5 bellows, silicon



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



PRF-GPA

Guide for aluminium profile, Parallel rails



BKGS

Backlash free coupling Gerwah®



TS01_TW01

Drylin® T linear slide, up to 7000 N

Complementary products



MRS

Stainless steel metric section rack, Stainless steel



TRMSS

Spur round rack, Stainless steel - module 1-5