
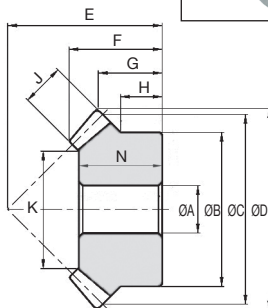


## Ratio 1:1

## Stainless steel 303

- Module 1 to 2.5
- Pressure angle 20°
- Teeth: Gleason
- Precision JIS B 1704 : 1978 grade 3
- Material :  
Stainless steel 303
- Gear hardness < 187HB
- Two gears required  
to make a pair

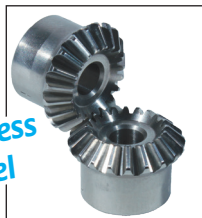

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-12%	On request

Part number	Module	Teeth		ØA	ØB	ØC	ØD	E	F	G	H	N	J	K	Weight (g)	Price each	
		Z	H7													1 à 5	6 à 10
SSB1-20-RA	1	20	6	16	20	21,41	20	13,95	10,71	8	12	5	9,86	0,019	42,57	€	
SSB1-25-RA		25	6	20	25	26,41	23	15,16	11,21	8	14	6	15,03	0,035	46,92	€	
SSB1-30-RA		30	8	24	30	31,41	28	17,71	13,71	10	16	6	19,03	0,057	57,50	€	
SSB1.5-20-RA	1,5	20	8	26	30	32,12	30	21,24	16,06	13	19	8	15,37	0,074	54,13	€	
SSB1.5-25-RA		25	10	30	37,5	39,62	34	22,25	16,31	11,5	19	9	19,54	0,11	67,68	€	
SSB1.5-30-RA		30	10	36	45	47,12	43	28,24	21,56	16	25	10	25,72	0,21	99,05	€	
SSB2-20-RA	2	20	12	34	40	42,83	37	24,89	18,41	14	22	10	21,72	0,15	76,49	€	
SSB2-25-RA		25	12	45	50	52,83	40	24,33	16,41	12,5	20	12	26,06	0,24	95,26	€	
SSB2-30-RA		30	12	45	60	62,83	50	29,43	21,41	12,5	25	12	36,06	0,37	138,61	€	
SSB2.5-20-RA	2,5	20	14	42	50	53,54	48	32,54	24,77	19	29	12	28,06	0,30	108,65	€	
SSB2.5-25-RA		25	16	55	62,5	66,04	50	30,41	20,52	15	26	15	34,57	0,46	145,19	€	
SSB2.5-30-RA		30	16	60	75	78,54	62	36,28	26,27	17	32	15	47,57	0,76	212,52	€	

Dimensions in mm

## Stainless steel 303

### Ratio

# 1,5:1 2:1 3:1

- Module 1 to 2.5
- Pressure angle 20°
- Teeth: Gleason
- Precision JIS B 1704 : 1978 grade 3
- Material :  
Stainless steel 303
- Gear hardness < 187HB
- Two gears required  
to make a pair



stainless  
steel

### DISCOUNTS



Qty	1+	6+	10+
Disc.	List	-12%	On request

Part number	Module	Teeth		ØA	ØB	ØC	ØD	E	F	G	H	N	J	K	Weight (g)	Price each 1 à 5
		Z	H7													
<b>Ratio 1,5:1</b>																
SSHB1.5-20-RA	1,5	20	8	25	30	33,13	33	18,63	11,54	8,83	17	9	17,05	0,063	55,11	€
SSHB1.5-30-RA		30	10	30	45	46,24	28	18,53	13,93	8	16	9	27,37	0,120	84,88	€
SSHB2-20-RA	2	20	10	35	40	44,18	45	25,06	16,39	13,33	22	11	21,34	0,160	82,29	€
SSHB2-30-RA		30	10	35	60	61,65	40	26,87	21,24	15	23	11	37,56	0,260	129,60	€
SSHB2.5-20-RA	2,5	20	12	40	50	55,22	55	31,06	19,24	14,16	28	15	27,42	0,280	118,05	€
SSHB2.5-30-RA		30	15	45	75	77,07	50	34,22	26,55	18	30	15	45,61	0,540	194,93	€
<b>Ratio 2:1</b>																
SSDB1.5-20-RA	1,5	20	8	25	30	33,61	46	25,54	16,9	14,75	24	10	17,28	0,088	62,51	€
SSDB1.5-40-RA		40	10	38	60	60,88	35	25,01	20,88	15	22	10	39,64	0,270	132,03	€
SSDB2-20-RA	2	20	12	32	40	44,81	60	34,16	21,2	18	32	15	20,92	0,190	92,67	€
SSDB2-40-RA		40	12	50	80	81,17	45	32,37	26,17	18	27	15	48,46	0,610	214,91	€
SSDB2.5-20-RA	2,5	20	12	40	50	56,01	75	43,78	26,5	22,5	41	20	24,56	0,400	144,01	€
SSDB2.5-40-RA		40	15	60	100	101,46	55	39,73	31,46	20	35	20	60,28	1,210	352,53	€

Dimensions in mm

Ratio  
1,5:1  
2:1  
3:1

Stainless steel 303

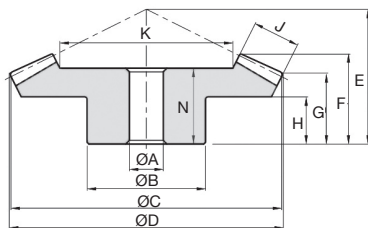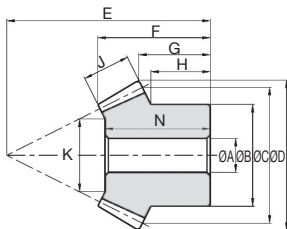

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-12%	On request

Part number	Module	Teeth		ØA	ØB	ØC	ØD	E	F	G	H	N	J	K	Weight (g)	Price each 1 à 5
		Z	H7													
<b>Ratio 3:1</b>																
SSTB1.5-15-RA	1.5	15	8	18	22,5	26,54	47	23,19	13,92	12,5	22,5	10	14,75	0,041	43,94 €	
SSTB1.5-45-RA		45	10	36	67,5	68,06	28	20,44	17,59	11	17	10	46,58	0,250	143,59 €	
SSTB2-15-RA	2	15	10	24	30	35,35	60	29,8	15,89	14	29	15	19,13	0,095	63,69 €	
SSTB2-45-RA		45	12	60	90	90,75	40	30,4	26,12	17	26	15	59,04	0,800	243,88 €	
SSTB2.5-15-RA	2.5	15	12	30	37,5	44,18	75	38,41	19,86	17,5	37	20	20,51	0,190	90,28 €	
SSTB2.5-45-RA		45	15	60	112,5	113,43	50	38,35	32,65	22	35	20	72,84	1,360	406,27 €	

Dimensions in mm

## Our other products



LFM2

Steel leadscrew,  
Medium carbon steel -  
2 threads



SLB

Indexing plunger,  
steel class 5.8



MPE

Hexagonal spacer,  
Steel



FTSN

Supported shaft for  
linear guide, Steel  
shaft / Aluminium  
support



BL8

Right angled gearbox,  
from 0.20 to 2 Nm




BAC105

Storage bin, 8mm



ACLCHAR

 Hinge for aluminium  
profile, With  
elongated holes



SR

Narrow spur rack,  
Stainless steel



AC144

Strike for toggle latch,  
22mm



H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NC2



SPIT

Floor mounting  
levelling plate, With  
anchoring point



BABS

630 Stainless steel  
compact ball pin,  
Hardened stainless  
steel

## Complementary products



ZHBRA

Plastic bevel gear,  
1,25:1 2:1 3:1



ZBRA

Machined plastic  
bevel gear, 1:1