
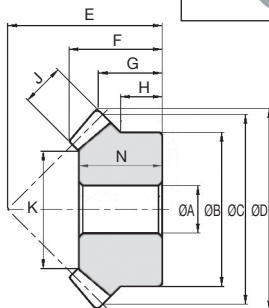


## Ratio 1:1

## Stainless steel 303

- Module 1 to 2.5
- Pressure angle 20°
- Teeth: Gleason
- Precision JIS B 1704 : 1978 grade 3
- Material :  
Stainless steel 303
- Gear hardness < 187HB
- Two gears required  
to make a pair

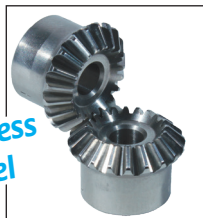

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-12%	On request

Part number	Module	Teeth		ØA	ØB	ØC	ØD	E	F	G	H	N	J	K	Weight (g)	Price each	
		Z	H7													1 à 5	6 à 10
SSB1-20-RA	1	20	6	16	20	21,41	20	13,95	10,71	8	12	5	9,86	0,019	42,57	€	
SSB1-25-RA		25	6	20	25	26,41	23	15,16	11,21	8	14	6	15,03	0,035	46,92	€	
SSB1-30-RA		30	8	24	30	31,41	28	17,71	13,71	10	16	6	19,03	0,057	57,50	€	
SSB1.5-20-RA	1,5	20	8	26	30	32,12	30	21,24	16,06	13	19	8	15,37	0,074	54,13	€	
SSB1.5-25-RA		25	10	30	37,5	39,62	34	22,25	16,31	11,5	19	9	19,54	0,11	67,68	€	
SSB1.5-30-RA		30	10	36	45	47,12	43	28,24	21,56	16	25	10	25,72	0,21	99,05	€	
SSB2-20-RA	2	20	12	34	40	42,83	37	24,89	18,41	14	22	10	21,72	0,15	76,49	€	
SSB2-25-RA		25	12	45	50	52,83	40	24,33	16,41	12,5	20	12	26,06	0,24	95,26	€	
SSB2-30-RA		30	12	45	60	62,83	50	29,43	21,41	12,5	25	12	36,06	0,37	138,61	€	
SSB2.5-20-RA	2,5	20	14	42	50	53,54	48	32,54	24,77	19	29	12	28,06	0,30	108,65	€	
SSB2.5-25-RA		25	16	55	62,5	66,04	50	30,41	20,52	15	26	15	34,57	0,46	145,19	€	
SSB2.5-30-RA		30	16	60	75	78,54	62	36,28	26,27	17	32	15	47,57	0,76	212,52	€	

Dimensions in mm

## Stainless steel 303

### Ratio

# 1,5:1 2:1 3:1

- Module 1 to 2.5
- Pressure angle 20°
- Teeth: Gleason
- Precision JIS B 1704 : 1978 grade 3
- Material :
- Stainless steel 303
- Gear hardness < 187HB
- Two gears required to make a pair



stainless  
steel

### DISCOUNTS



Qty	1+	6+	10+
Disc.	List	-12%	On request

Part number	Module	Teeth		ØA	ØB	ØC	ØD	E	F	G	H	N	J	K	Weight (g)	Price each 1 à 5
		Z	H7													
<b>Ratio 1,5:1</b>																
SSHB1.5-20-RA	1,5	20	8	25	30	33,13	33	18,63	11,54	8,83	17	9	17,05	0,063	55,11	€
SSHB1.5-30-RA		30	10	30	45	46,24	28	18,53	13,93	8	16	9	27,37	0,120	84,88	€
SSHB2-20-RA	2	20	10	35	40	44,18	45	25,06	16,39	13,33	22	11	21,34	0,160	82,29	€
SSHB2-30-RA		30	10	35	60	61,65	40	26,87	21,24	15	23	11	37,56	0,260	129,60	€
SSHB2.5-20-RA	2,5	20	12	40	50	55,22	55	31,06	19,24	14,16	28	15	27,42	0,280	118,05	€
SSHB2.5-30-RA		30	15	45	75	77,07	50	34,22	26,55	18	30	15	45,61	0,540	194,93	€
<b>Ratio 2:1</b>																
SSDB1.5-20-RA	1,5	20	8	25	30	33,61	46	25,54	16,9	14,75	24	10	17,28	0,088	62,51	€
SSDB1.5-40-RA		40	10	38	60	60,88	35	25,01	20,88	15	22	10	39,64	0,270	132,03	€
SSDB2-20-RA	2	20	12	32	40	44,81	60	34,16	21,2	18	32	15	20,92	0,190	92,67	€
SSDB2-40-RA		40	12	50	80	81,17	45	32,37	26,17	18	27	15	48,46	0,610	214,91	€
SSDB2.5-20-RA	2,5	20	12	40	50	56,01	75	43,78	26,5	22,5	41	20	24,56	0,400	144,01	€
SSDB2.5-40-RA		40	15	60	100	101,46	55	39,73	31,46	20	35	20	60,28	1,210	352,53	€

Dimensions in mm

Ratio  
1,5:1  
2:1  
3:1

Stainless steel 303

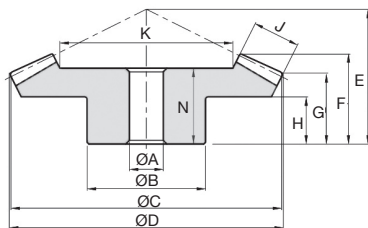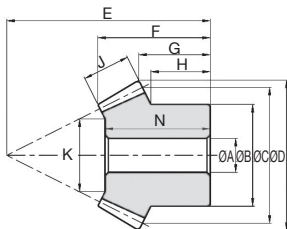

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-12%	On request

Part number	Module	Teeth		ØA	ØB	ØC	ØD	E	F	G	H	N	J	K	Weight (g)	Price each
		Z	H7													
<b>Ratio 3:1</b>																
SSTB1.5-15-RA	1.5	15	8	18	22,5	26,54	47	23,19	13,92	12,5	22,5	10	14,75	0,041	43,94	€
SSTB1.5-45-RA		45	10	36	67,5	68,06	28	20,44	17,59	11	17	10	46,58	0,250	143,59	€
SSTB2-15-RA	2	15	10	24	30	35,35	60	29,8	15,89	14	29	15	19,13	0,095	63,69	€
SSTB2-45-RA		45	12	60	90	90,75	40	30,4	26,12	17	26	15	59,04	0,800	243,88	€
SSTB2.5-15-RA	2.5	15	12	30	37,5	44,18	75	38,41	19,86	17,5	37	20	20,51	0,190	90,28	€
SSTB2.5-45-RA		45	15	60	112,5	113,43	50	38,35	32,65	22	35	20	72,84	1,360	406,27	€

Dimensions in mm

## Our other products



LBE

Miniature closed linear bearing, Miniature



MBF

Threaded blocking clamp, Threaded locking clamp



P45

Worm and wheel gear reducer, up to 40 Nm



SSB

Stainless steel bevel gear, 1:1



 
LRRRA

Latch with locking system, Aluminium




ERT

Sliding nut, For T slot




B

 Steel bevel gear, 1:1



PO

 Pull handle - Multi-sector, Smooth hole



H1

Crossed helical gear crossed axis at 90°



KITbuh

24V DC motorisation kit, Planetary gears



PAT85

Pressed stainless steel articulating foot



KSTM

Igubal® pillow block bearing, Polymer

## Complementary products



ZHBRA

Plastic bevel gear, 1,25:1 2:1 3:1



ZBRA

Machined plastic bevel gear, 1:1