


# Shock absorber - stop collar




## STC

## Mounting accessory

- Stop collar for shock absorber
- Please note: for certain shock absorbers, the use of this stop collar is essential

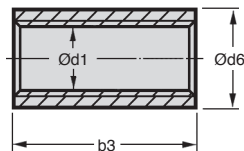

STC10 to 12

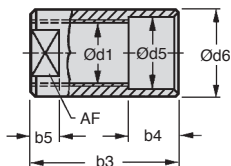

STC14 to 25



Typical application

### DISCOUNTS

Qty	1+	4+	6+
Disc.	List	-10%	On request

Part number	Ød1	Ød5	Ød6	b3	b4	b5	AF	For shock-absorber	Stock*	Price each
										1 to 3
STC10	M10x1	-	14,3	20	-	-	-	MC25	✓	13,42 €
STC12	M12x1	-	16,0	20	-	-	-	MC75	✓	13,42 €
STC14	M14x1,5	14,5	18,0	19	12	6	13	MC150	-	14,57 €
STC20	M20x1,5	20,5	25,0	25	12	8	22	RMSA500	-	21,71 €
STC25	M25x1,5	25,5	32,0	45	16	10	27	RMSA600-900	✓	30,86 €

\*Depending on availability - Dimensions in mm

## Our other products



MSP3815

Masterplate® glueable insert rectangular, rectangular with nut



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



CTZY

Diabolo shaped elastomeric mount, Steel



SEH

Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless ...




MSP23

Masterplate® cylindrical insert Ø23, Cylindrical Ø23 with threaded s...



PGM86-M5

 Push/Pull handle, Thermoplastic




PRL

Wear strip for slat top chain, L profile to be clipped



PDD

 Actuating plunger, Non-rotating detector shaft



B

Steel bevel gear, 1:1



CHAR

Spring hinge, screwed



SH3

Parallel axis helical gear, Machined plastic (delrin)



BSP

Compact precision slide, from 156 N to 980 N

## Complementary products



RMSA

Adjustable shock-absorber, Adjustable



MC

Self-compensating shock-absorber, Self-compensating - without adjust...