


Shock absorber - stop collar




STC

Mounting accessory

- Stop collar for shock absorber
- Please note: for certain shock absorbers, the use of this stop collar is essential

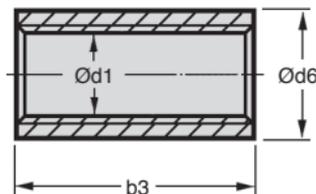

STC10 to 12

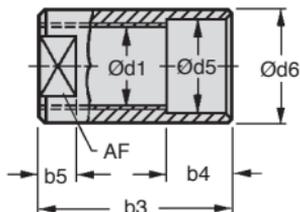

STC14 to 25



Typical application


DISCOUNTS

Qty	1+	4+	6+
Disc.	List	-10%	On request

Part number	Ød1	Ød5	Ød6	b3	b4	b5	AF	For shock-absorber	Stock*	Price each
										1 to 3
STC10	M10x1	-	14,3	20	-	-	-	MC25	✓	13,42 €
STC12	M12x1	-	16,0	20	-	-	-	MC75	✓	13,42 €
STC14	M14x1,5	14,5	18,0	19	12	6	13	MC150	-	14,57 €
STC20	M20x1,5	20,5	25,0	25	12	8	22	RMSA500	-	21,71 €
STC25	M25x1,5	25,5	32,0	45	16	10	27	RMSA600-900	✓	30,86 €

*Depending on availability - Dimensions in mm

Our other products

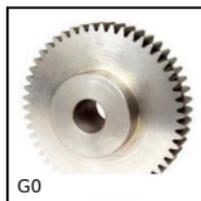

G0

Steel spur gear, Steel 20NCD2



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - steel



PRF_BV

Screw block, Panel addition and fastening



E20

Right angle helical reducers, from 0.60 to 3.84 Nm



HRV

V-rail guidance Simple Select® system, Rail with carriage



DB

Steel bevel gear, 2:1



BPM

Slotted spring plunger with ball tip, Stainless steel 303



RTT

Locking Assembly, Medium/high torque



M1

Worm, Non hardened steel




NCT

Square tube connector, Fixed angle



Gdal

Double universal joint eco series, Low duty

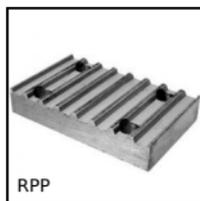

RPP

Connecting plate for RPP type timing belts, RPP8

Complementary products



RMSA

Adjustable shock-absorber, Adjustable



MC

Self-compensating shock-absorber, Self-compensating - without adjust...