


Shock absorber - stop collar




STC

Mounting accessory

- **Stop collar for shock absorber**
- Please note: for certain shock absorbers, the use of this stop collar is essential

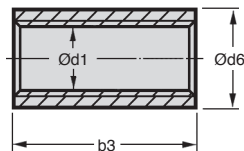

STC10 to 12

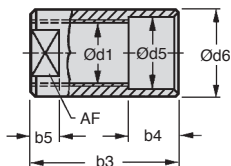

STC14 to 25



Typical application

DISCOUNTS

Qty	1+	4+	6+
Disc.	List	-10%	On request

Part number	Ød1	Ød5	Ød6	b3	b4	b5	AF	For shock-absorber	Stock*	Price each 1 to 3
STC10	M10x1	-	14,3	20	-	-	-	MC25	✓	13,42 €
STC12	M12x1	-	16,0	20	-	-	-	MC75	✓	13,42 €
STC14	M14x1,5	14,5	18,0	19	12	6	13	MC150	-	14,57 €
STC20	M20x1,5	20,5	25,0	25	12	8	22	RMSA500	-	21,71 €
STC25	M25x1,5	25,5	32,0	45	16	10	27	RMSA600-900	✓	30,86 €

*Depending on availability - Dimensions in mm

Our other products



METC

Flanged sintered bronze bush, Self-lubricating sintered bronze



TBEBase

Base plate for economic mini-table, Allows X-Y cross tables



HCSS

Set screw with hexagonal socket, Cup point



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual



DIA

Ring operated locking bolt, with ring



RPCplss

Swivel castor with double brake, Stainless steel - Polyamide



VTH

Hexagonal headed bolts, Steel class 8.8



TAC_SS

Stainless steel rigging screw (hook/eye), Stainless steel



CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



 
SBF

Sealed flange bearing unit for Food Industry, cover



T25-BAR

T type tooth bar stock, T2.5



PF70

Worm and wheel gear reducer, up to 164 Nm

Complementary products



RMSA

Adjustable shock-absorber, Adjustable



MC

Self-compensating shock-absorber, Self-compensating - without adjust...