



- For guidance and transport

- Easy maintenance

- Materials:

- base: green PVC

- brush: PA6 transparent straight fibres


- rail: galvanised steel

Avantages

- In case of they need to be replaced, these strip brushes can be quickly removed from the rails
- Their use is recommended in applications where the fibres will be subject to heavy wear.



Typical application

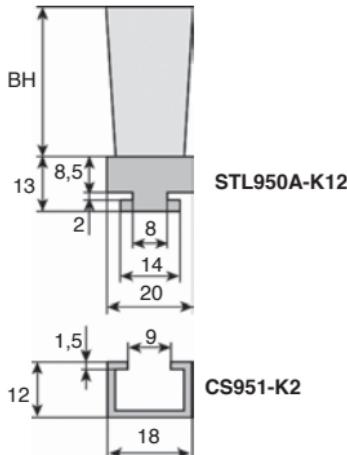

DISCOUNTS

Qty	1+	50+	150+	250+
Disc.	List	-10%	-15%	On request

Part number	Length L (mm)	Fibre Ø (mm)	BH	Stock*	Price each 1 to 49
Brush					
STL950A-K12	2000	0,2	8	✓	23,96 €
Rail					
CS951-K2	2000	-	-	✓	17,51 €


*Depending on availability - Dimensions in mm

Our other products



CHAu

Screwed hinge, 270°

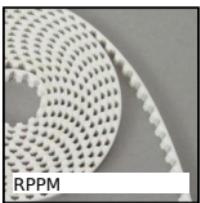

RPPM

RPP type belt per
metre, RPP5 Steel
cored polyurethane



ZG4

Plastic spur gear,
Machined plastic
(delrin)



COA-COG

Surface mounting
plate, Surface
mounting plate for
clevis



HTD8M_30

HTD Heavy duty
timing pulley, HTD8
Steel



RPP

Connecting plate for
RPP type timing belts,
RPP8



RVM14

Manual worm and
wheel gearbox,
Worm/wheel



T5_T10M

T type timing belt per
metre, T10 Steel
cored polyurethane



MEB

Moulded plastic bevel
gear (nylon), 1:1



PRF-GPB

Guide for aluminium
profile, Rail for 8mm
wide slots



GGP


Male wing knob,
Technopolymer with
stainless steel spindle



ESCON

Speed controller 5A
accessories, Kit of 4
cables for DC motor

Complementary products

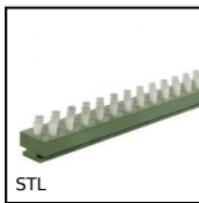


STL

Guidance brush -
Brush, Brush



GMC_GMK_BR

Guiding profile clamp,
Flat or rounded

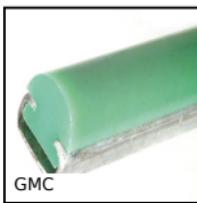

GMC

Flat profile - Round
guide, Flat profile -
round guide



APB_F

Adjusting rod for
clamp - Male,
Threaded